



Drive Isolation Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83B4007G29

75.0 KVA 60 HZ 3 PH 5.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 230 VOLTS (LINE-LINE)
SECONDARY (X) 230 VOLTS (LINE-LINE)
133 VOLTS (LINE-NEUTRAL)

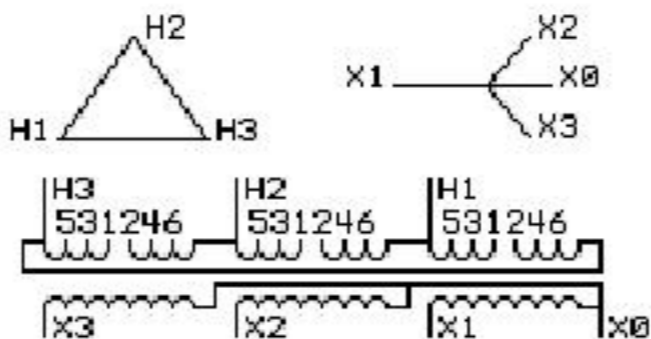

JUMPER CONNECTION


TAP	VOLTS
1-2	241
3-4	230
5-6	217

NET WGT
620 LB
281.2 Kg

60509
XV374
NOG
030216

INSPECTION
&
FINAL TEST
N610!

COIL TAP ARRANGEMENT

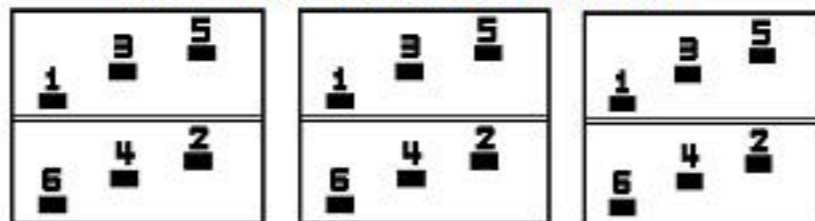

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B401AAP074

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.


X3 - X2 - X1 - -
- H3 - H2 - H1

Note: X0 Terminal at the bottom

X1 - -
X2 - H1
X3 - H2 - H1
X3 - X2 - X1 -
X3 - H3 - H2 - H1
X0



2M000000

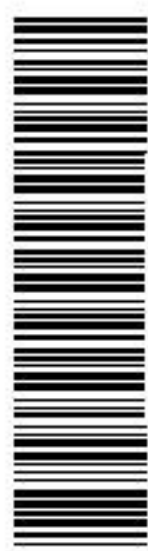

3M000000