

GE Drive Isolation Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M0000000

Catalog Number **Type QL**

9D3A093ABAF00A2T00


9T83B4008G02

93.0 KVA 60 HZ 3 PH 6 % IMP


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 460 VOLTS (LINE-LINE)

SECONDARY (X) 230 VOLTS (LINE-LINE)

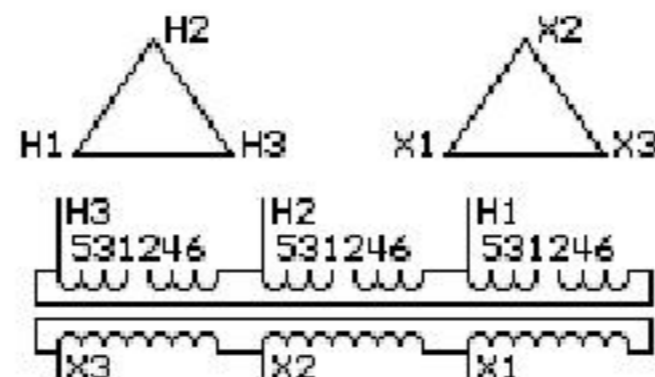

COIL TAP ARRANGEMENT

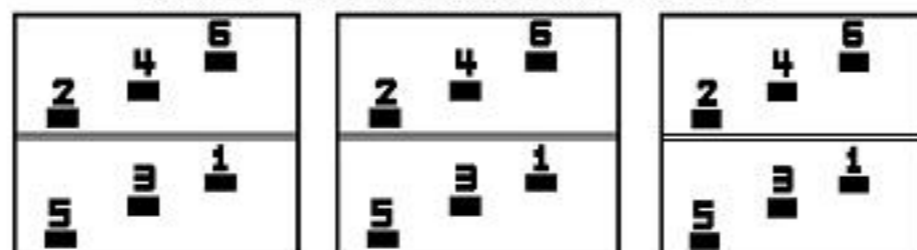

JUMPER CONNECTION	
TAP	VOLTS
1-2	483
3-4	460
5-6	437

NET WGT
765 LB
347.0 Kg

59219

KU375

NOG

012716

INSPECTION
&
FINAL TEST
N605!



ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline: 303B401AAP075

ALUMINUM CONDUCTOR

PRIMARY: 10 KV BIL

SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

X3 - X2 - X1 - -
- H3 - H2 - H1

Note: Standard



2M0000000



3M0000000

X3 - X2 - X1 -
- H3 - H2 - H1
X3 - X2 - X1 -
- H3 - H2 - H1