




# Drive Isolation Transformer

Catalog Number **9T83B4012G26**

**220.0 KVA 60 HZ 3 PH 3.3 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: Q1

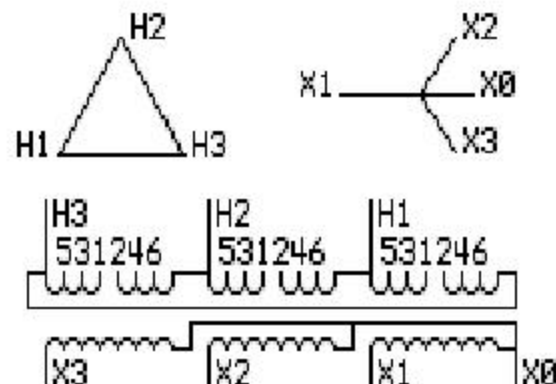


### JUMPER CONNECTION

TAP	VOLTS
1-2	607
3-4	575
5-6	546

PRIMARY (H) 575 VOLTS (LINE-LINE)  
 SECONDARY (X) 460 VOLTS (LINE-LINE)  
 266 VOLTS (LINE-NEUTRAL)

### COIL TAP ARRANGEMENT

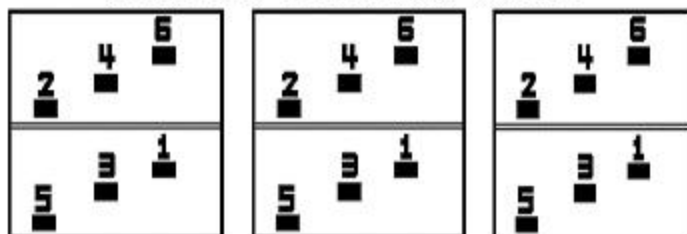

NET WGT 1585 LB 719.0 Kg

111411 N147! FC79

9T83B4012G 16018 NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G79

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

26



Outline: 303B919AAP077  
Assembled in Mexico

INSPECTION & FINAL TEST  
N147!