




Transformer

Catalog Number 9T83B4012G82

9D3A220AAAQ00A2T00

220.0 KVA 60 HZ 3 PH 6.9 % IMP


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

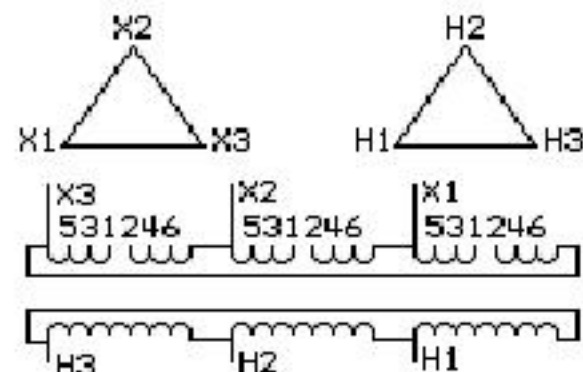

JUMPER CONNECTION	
TAP	VOLTS
1-2	505
3-4	480
5-6	455

PRIMARY (X) 480 VOLTS (LINE-LINE)
 SECONDARY (H) 575 VOLTS (LINE-LINE)

COIL TAP ARRANGEMENT

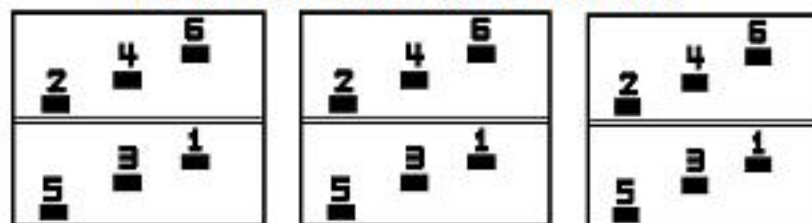

NET WGT 1590 LB 721.2 Kg

081115 N533! XV377
55744 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP077
Assembled in Mexico

INSPECTION & FINAL TEST
N533!

