




# Transformer

Catalog Number 9T83B5127

**9Q3A225AFAK00A2T00**

225.0 KVA 60 HZ 3 PH 7.3 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

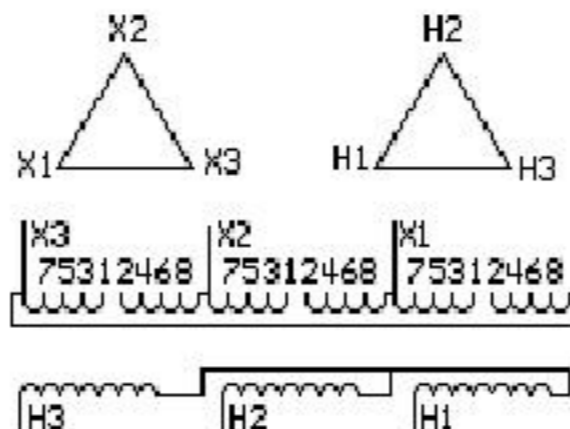


### JUMPER CONNECTION

TAP	VOLTS
1-2	221
2-3	215
3-4	208
4-5	203
5-6	197
6-7	191
7-8	185

PRIMARY (X) 208 VOLTS (LINE-LINE)  
 SECONDARY (H) 400 VOLTS (LINE-LINE)

### COIL TAP ARRANGEMENT

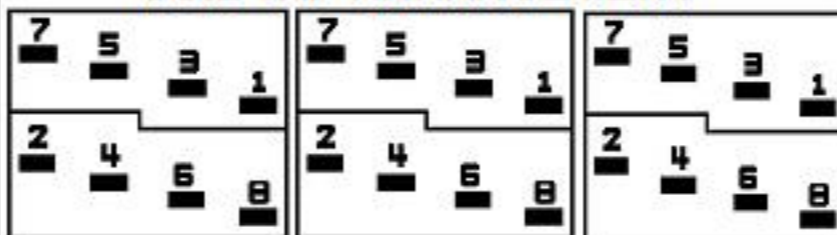

NET WGT 1590 LB 721.2 Kg

081115 N533! XV377  
46848 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G 88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP077  
Assembled in Mexico

INSPECTION & FINAL TEST  
N533!

