




Transformer

Catalog Number 9T83B5497

9Q3A225AMAA00A2T00

225.0 KVA 60 HZ 3 PH 7.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: Q1

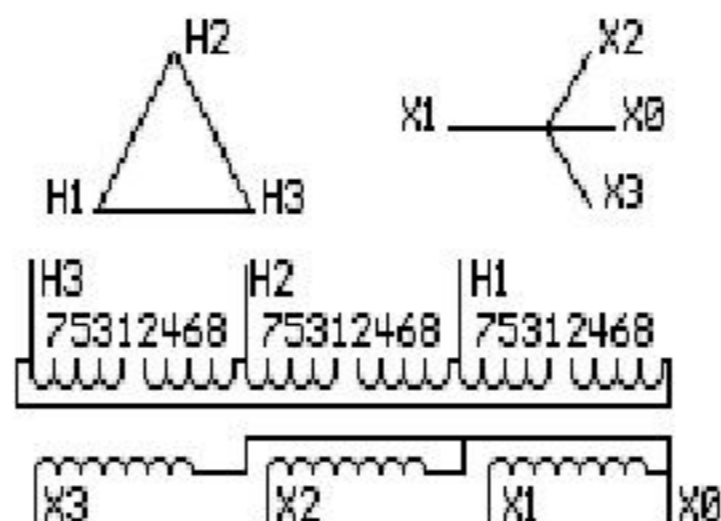


JUMPER CONNECTION

TAP	VOLTS
1-2	417
2-3	411
3-4	400
4-5	392
5-6	379
6-7	373
7-8	360


PRIMARY (H) 400 VOLTS (LINE-LINE)
 SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

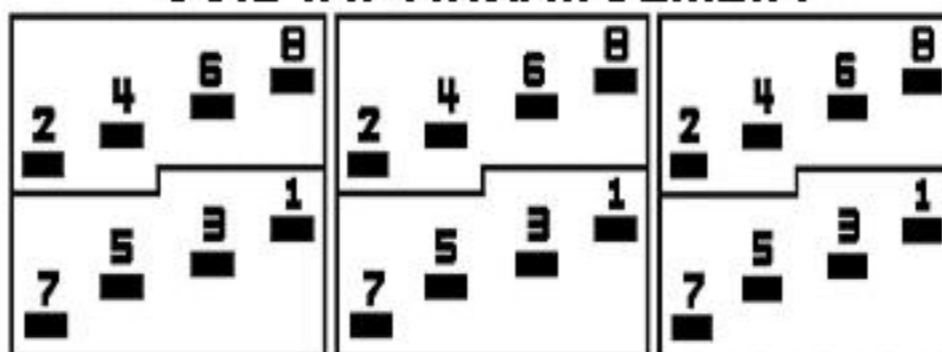

NET WGT 1590 LB 721.2 Kg

101715 N542! XN377
58001 NOG

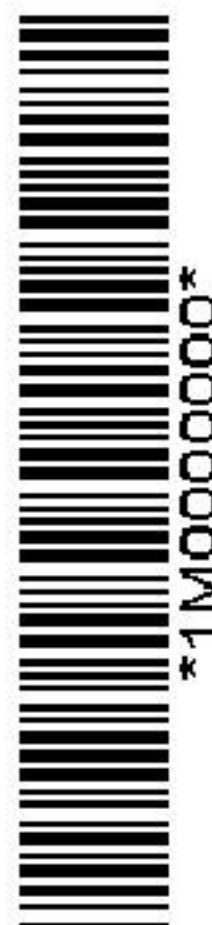

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES

CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 303B919AAP077

Assembled in Mexico

INSPECTION & FINAL TEST

N542!