



# Transformer


Catalog Number 9T83B5579

**9Q3A500AAAF00A2T00**


500.0 KVA 60 HZ 3 PH 4.1 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

PRIMARY (H) 480 VOLTS (LINE-LINE)  
SECONDARY (X) 230 VOLTS (LINE-LINE)

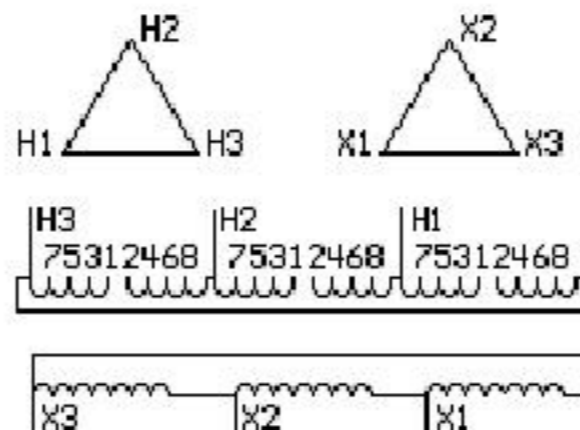

### COIL TAP ARRANGEMENT

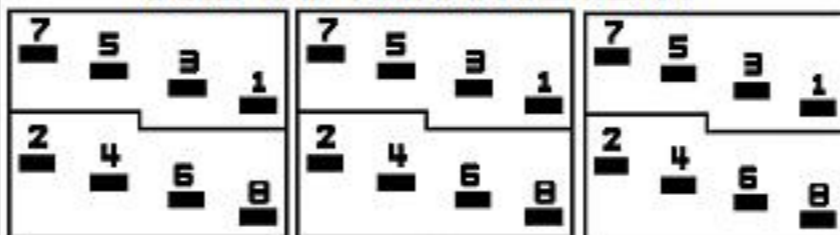

JUMPER CONNECTION

TAP	VOLTS
1-2	504
2-3	493
3-4	480
4-5	471
5-6	460
6-7	449
7-8	427

NET WGT 3400 LB 1542.2 Kg

091415 N538! YF379

55994 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179  
Assembled in Mexico

INSPECTION & FINAL TEST  
N538!

