



Transformer



1M000000

Catalog Number


Type QL

9T83B6491G05

15.0 KVA 50/60 HZ 3 PH 8.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 400 VOLTS (LINE-LINE)

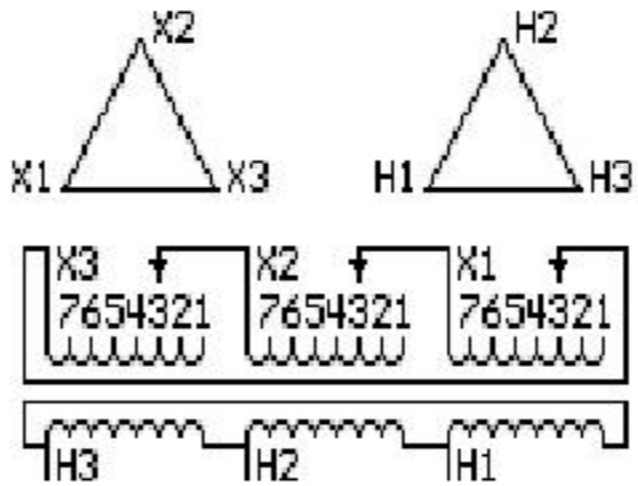


JUMPER CONNECTION	
TAP	VOLTS
1	218
2	214
3	208
4	203
5	198
6	192
7	188

NET WGT
240 LB
108.9 Kg

57885
XU371
NOG
092815

INSPECTION
&
FINAL TEST
N540!

COIL TAP ARRANGEMENT

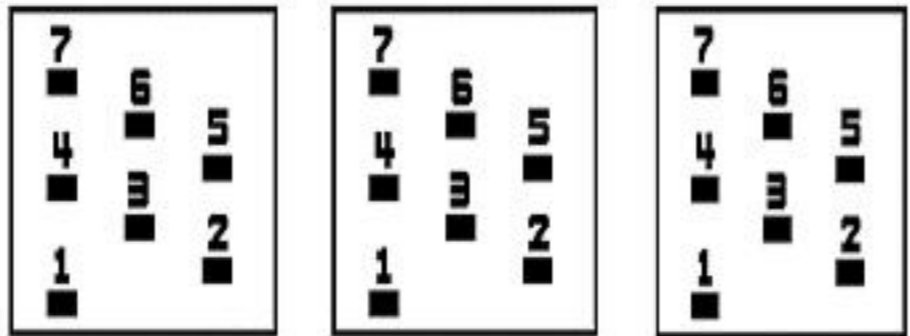

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline: 303B401AAP071
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

H3 - H2 - H1 - -
- X3 - X2 - X1

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note: Standard

H3 - H2 - H1 - -
- X3 - X2 - X1

