

Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83C2571G83

25.0 KVA 60 HZ 1 PH 3.7 % IMP

40 C AMB. 80 C RISE 220 C SYSTEM IS-19C

NOG

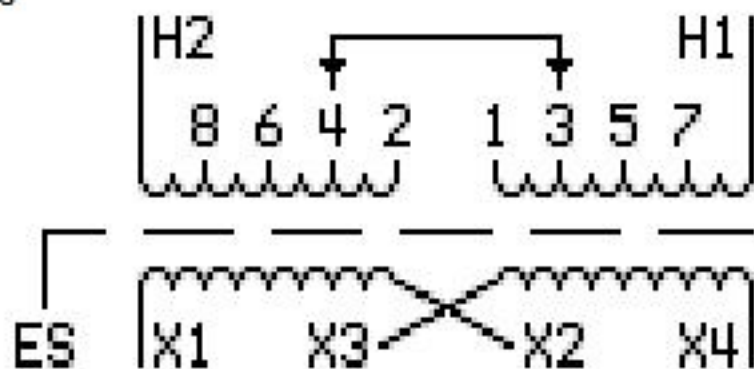

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

PRIMARY LINES ON H1-H2				SECONDARY LINES ON X1-X4	
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT
216	8-H1,7-H2	431	8-7	120	X1-X3,X2-X4
230	6-H1,5-H2	445	7-6	240	X2-X3
240	4-H1,3-H2	459	6-5		
250	2-H1,1-H2	469	5-4		
		480	4-3		
		491	3-2		
		501	2-1		

NET WGT
460 LB
208.7 Kg
YF172
34404
021516

INSPECTION & FINAL TEST
N608!

COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B406AAP072 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

H2 X4 - H1 X1 - -
- X3 - X2 - -

Note: Standard

H2 X4 - H1 X1 - -
- X3 - X2 - -
H2 X4 - H1 X1 - -
- X3 - X2 - -

