



Transformer




Catalog Number **9Q1C050AXAS00B2T30** Type QL
9T83C2573G20

50.0 KVA 60 HZ 1 PH 4.5 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

NOG

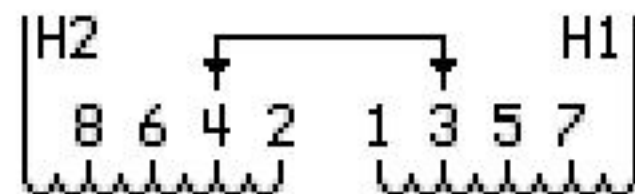

PRIMARY				SECONDARY	
UOLTS	CONNECT	UOLTS	CONNECT	UOLTS	CONNECT
215	8-H1,7-H2	430	8-7	120	X1-X3,X2-X4
227	6-H1,5-H2	442	7-6	240	X2-X3
240	4-H1,3-H2	454	6-5		
253	2-H1,1-H2	467	5-4		
		480	4-3		
		493	3-2		

NET WGT
500 LB
226.8 Kg

55331
090715

INSPECTION
&
FINAL TEST
N5371

COIL TAP ARRANGEMENT



LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R. ENCLOSURE (IP32) WHEN PROVIDED SHIELD. 9T18Y4317G06

Outline: 303B406AAP073 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 X1 - X2 X4 - -

- - H2 - - H1

Note: Standard

X3 X1 - X2 X4 -
- - H2 - - H1



X3 X1 - X2 X4 -
- - H2 - - H1

