



Transformer




Catalog Number **9Q1C050AAAS00B2T30** Type QL

9T83C2573G24

50.0 KVA 60 HZ 1 PH 4.5 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

NOG

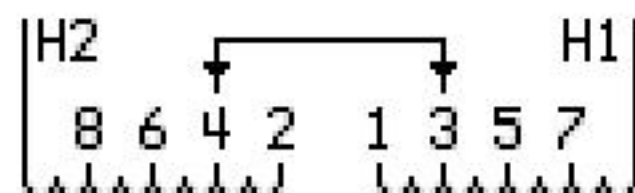

9T83B6453 9T83B6453 150921JA
 0 303B401AAP073 YNNN 40150220IS-19CQL 3 60AL100155N45.00
 5.8 415 230(+2,-4 2.40%) 575 E1 I
 09T18Y4317G05202020NN 2F0KRLBGSALE 01475A804CAG1
 29 N01 NXU373BENSALE0 45.000230(+2,-4 2.40%)
 575 0909NN N9T18Y43
 17G05TRANSFORMER ENERGY8-NOG X0 0

52091300044018000

SECONDARY		PRIMARY	
LINES ON X1-X4	VOLTS CONNECT	LINES ON H1-H2	VOLTS CONNECT
	215	8-H1,7-H2	430

NET WGT
500 LB

226.8 Kg



55331

092115

INSPECTION
&
FINAL TEST

N539!

COIL TAP ARRANGEMENT

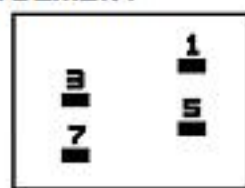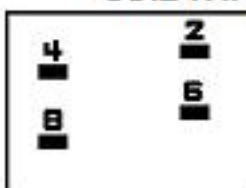

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B406AAP073 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 X1 - X2 X4 - -

- - H2 - - H1

Note: Standard

X3 X1 - X2 X4 -
 - - H2 - - H1
 X3 X1 - X2 X4 -
 - - H2 - - H1

