

GE Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER




Catalog Number **Type QL**

9T83C2573G61

50.0 KVA 60 HZ 1 PH 5.1 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

NOG


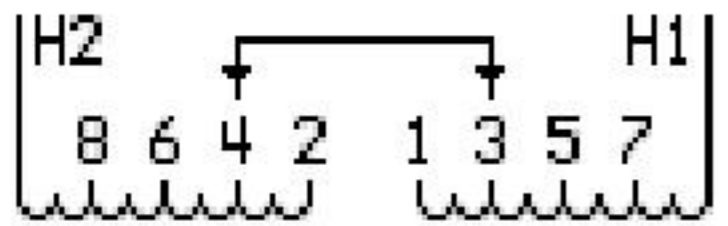


PRIMARY LINES ON H1-H2				SECONDARY LINES ON X1-X4			
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT
215	8-H1, 7-H2	429	8-7	120	X1-X3, X2-X4		
227	6-H1, 5-H2	442	7-6	240	X2-X3		
240	4-H1, 3-H2	455	6-5				
253	2-H1, 1-H2	467	5-4				
		480	4-3				
		493	3-2				

NET WGT
500 LB
226.8 Kg
XV173
59027
011916

INSPECTION & FINAL TEST
N604!

COIL TAP ARRANGEMENT

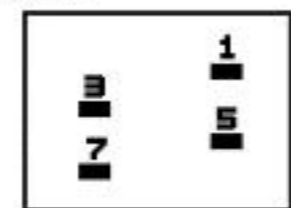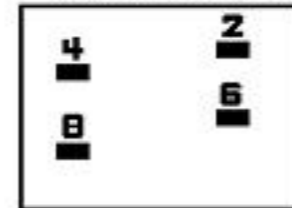

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B406AAP073 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

