



Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83C2575

100.0 KVA 60 HZ 1 PH 5.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG


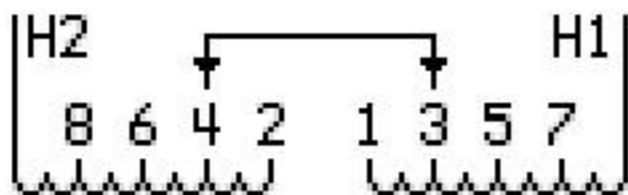


PRIMARY LINES ON H1-H2				SECONDARY LINES ON X1-X4			
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT		
218	8-H1,7-H2	436	8-7	120	X1-X3,X2-X4		
229	6-H1,5-H2	447	7-6	240	X2-X3		
240	4-H1,3-H2	458	6-5				
251	2-H1,1-H2	469	5-4				
		480	4-3				
		491	3-2				

NET WGT
1050 LB
476.3 Kg
YF175
60658
031816

INSPECTION & FINAL TEST
N612!

COIL TAP ARRANGEMENT

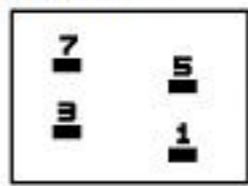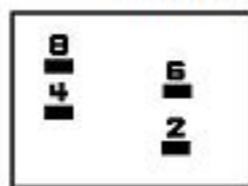

LISTED 769G

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G 77

Outline: 303B932AAP075 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

X3 X4 - X2 X1 - -
- - H2 - - H1

Note: Standard

X3 X4 - X2 X1 -
- - H2 - - H1
X3 X4 - X2 X1 -
- - H2 - - H1



2M000000



3M000000