

Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83C2575G80

100.0 KVA 60 HZ 1 PH 2.3 % IMP

40 C AMB. 80 C RISE 220 C SYSTEM IS-19C

NOG


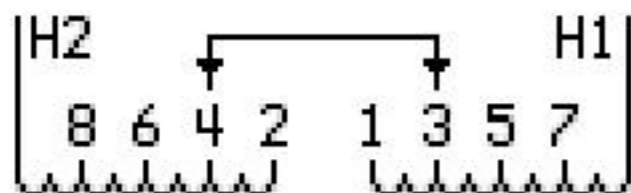


PRIMARY LINES ON H1-H2				SECONDARY LINES ON X1-X4			
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT		
219	8-H1,7-H2	438	8-7	120	X1-X3,X2-X4		
226	6-H1,5-H2	445	7-6	240	X2-X3		
240	4-H1,3-H2	452	6-5				
254	2-H1,1-H2	466	5-4				
		480	4-3				
		494	3-2				
		508	2-1				

NET WGT
1675 LB
759.8 Kg
YF176
60563
031516

INSPECTION & FINAL TEST
N612!

COIL TAP ARRANGEMENT

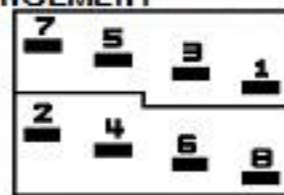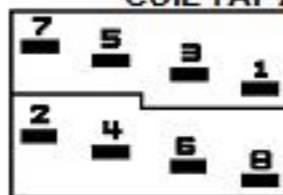

LISTED 769G

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G 88

Outline: 303B932AAP076 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 X4 - X2 X1 - -
- - H2 - - H1

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note: Standard

X3 X4 - X2 X1 - -
- - H2 - - H1
X3 X4 - X2 X1 - -
- - H2 - - H1

