

# Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



\*1M000000\*

Catalog Number


Type QL

9T83C2576

167 KVA 60 HZ 1 PH 4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

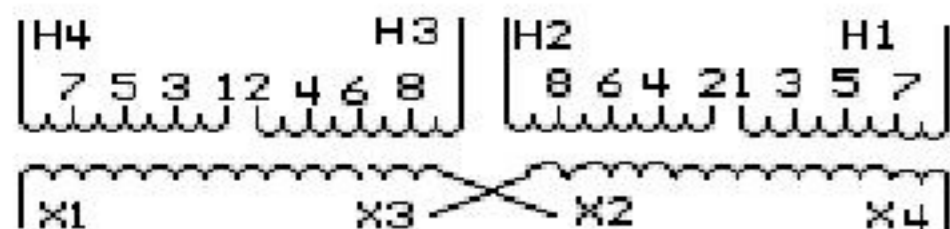

Primary  
Lines on H1-H4

Secondary  
Lines on X1-X4

Volts	Connect H1-H3, H2-H4	Volts	Connect H2-H3	Volts	Connect X1-X3, X2-X4
212	7-8	424	7-8	120	X1-X3, X2-X4
226	5-6	438	6-7	240	X2-X3
240	3-4	452	5-6		
254	1-2	466	4-5		
		480	3-4		
		494	2-3		
		508	1-2		

NET WGT

1675 LB

759.8 Kg

YF176

60659

031816


INSPECTION

&

FINAL TEST

N612!

COIL TAP ARRANGEMENT

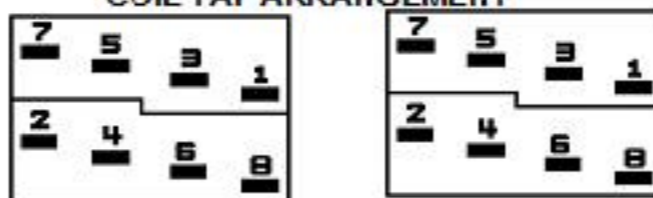

LISTED 769G

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G 88

Outline: 303B932AAP076 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES  
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



\*2M000000\*



\*3M000000\*