



Transformer




Catalog Number **9Q1C100AAAS00A2T00** Type QL

9T83C2865

9T83C2865

100.0 KVA 60 HZ 1 PH 5.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

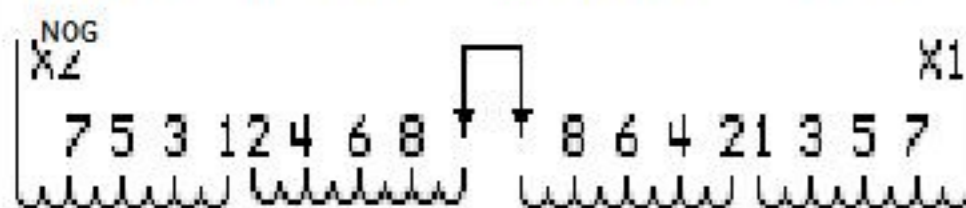

9T83C2815 9T83C2815 150921HB
 7 303B932AAP075 YNNN 40150220IS-19CQL 1 60CU100111N100.0
 6 1050 120x240(+2,-4 2.50%240/480 E1 I
 09T18Y4322G77615020NN 2FDHITCGENSALE 01475A1221ECG
 004 N01 NYF175GENSALE0 100.000120x240(+2,-4 2.50%)
 240/480 0705NN N9T18Y43
 22G77TRANSFORMER ENERGY8-NOG X0 0

51130000061000000


SECONDARY
 LINES ON X1-X4
 TS CONNECT

PRIMARY
 LINES ON H1-H2
 VOLTS CONNECT VOL
 436 7-8 12

NET WGT
 1050 LB
 476.3 Kg
 57753
 092115

INSPECTION
 &
 FINAL TEST
 N539!

COIL TAP ARRANGEMENT

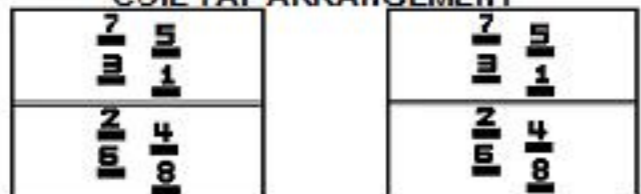

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G 77

Outline: 303B932AAP075 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 X4 - X2 X1 - -

- - H2 - - H1

Note: Standard

X1 - - H1
 X2 - - H1
 X3 X4 - - H2
 X3 X4 - - H2

