




# Transformer

Catalog Number 9T83C6779

## 9Q3C500AYBJ00A2T00

500.0 KVA 60 HZ 3 PH 3.2 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

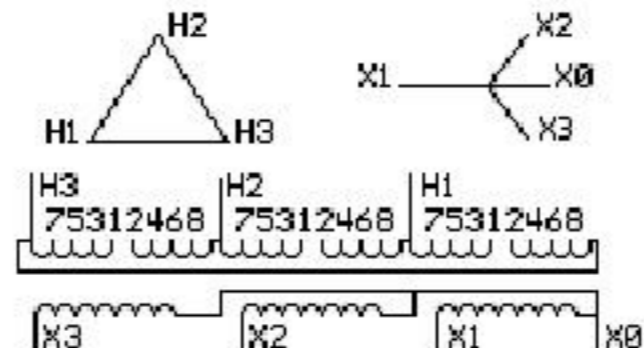


### JUMPER CONNECTION

TAP	VOLTS
1-2	461
2-3	450
3-4	440
4-5	428
5-6	417
6-7	406
7-8	395

PRIMARY (H) 440 VOLTS (LINE-LINE)  
 SECONDARY (X) 380 VOLTS (LINE-LINE)  
 219 VOLTS (LINE-NEUTRAL)

### COIL TAP ARRANGEMENT

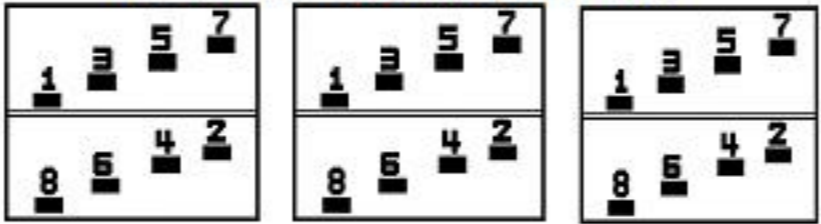

NET WGT 4050 LB 1837.1 Kg

090115 N536! YF379  
 55794 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G 68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES  
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179  
 Assembled in Mexico

INSPECTION & FINAL TEST  
 N536!

