

Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M0000000

X4

X4

Catalog Number Type QL


9Q3C075ABAC00A2T00

9T83C6984

75.0 KVA 60 HZ 3 PH 6.5 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOT FOR SALE FOR USE IN THE UNITED STATES

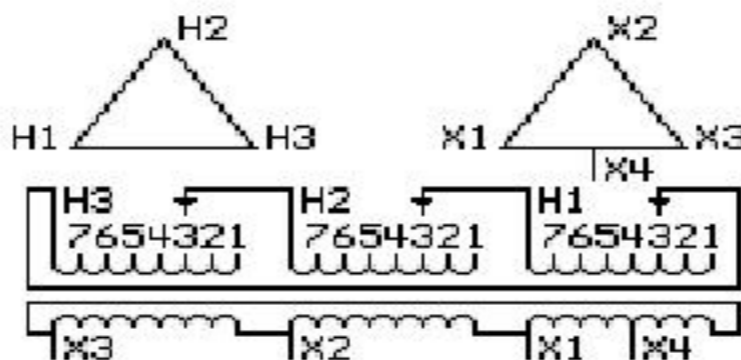

JUMPER CONNECTION	
TAP	VOLTS
1	484
2	473
3	460
4	447
5	436
6	425
7	415

NET WGT
710 LB
322.1 Kg


60595
XV374

NOG
031816

INSPECTION
&
FINAL TEST
N612!

PRIMARY (H) 460 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)
120 VOLTS (1 PH MDTAP)

COIL TAP ARRANGEMENT

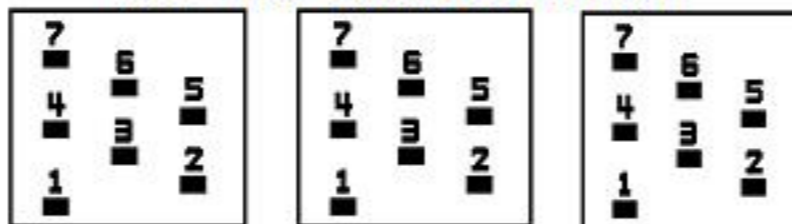

LISTED 769G

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline: 303B401AAP074

COPPER CONDUCTOR

PRIMARY: 10 KV BIL

SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Assembled in Mexico

X3 - X2 - X1 - X4
- H3 - H2 - H1

Note: Mid-Tap

X1 - X2 - X3 - H1 - H2 - H3

X1 - X2 - X3 - H1 - H2 - H3



2M0000000



3M0000000