




Transformer

Catalog Number 9T83C7089G51

9Q3C400MAZ01A03RL0T

400.0 KVA 60 HZ 3 PH 3 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL-WP

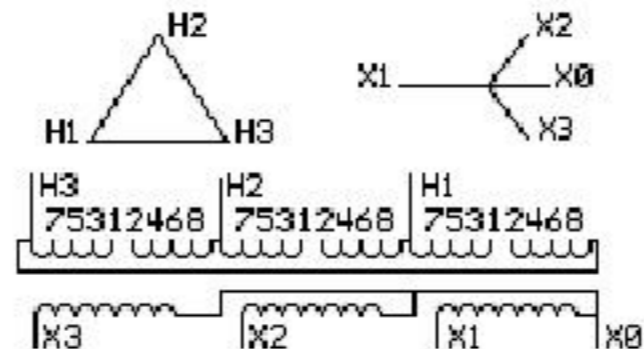


JUMPER CONNECTION

TAP	VOLTS
1-2	420
2-3	410
3-4	400
4-5	391
5-6	381
6-7	371
7-8	362

PRIMARY (H) 400 VOLTS (LINE-LINE)
 SECONDARY (X) 220 VOLTS (LINE-LINE)
 127 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

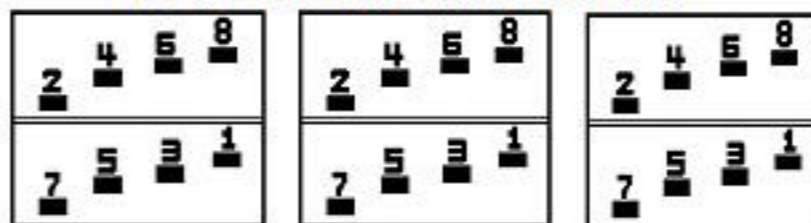

NET WGT 4050 LB 1837.1 Kg

090115 N536! YF379
 55795 NOG

ENCLOSURE TYPE 3R (IP22)

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179
 Assembled in Mexico

INSPECTION & FINAL TEST
 N536!

