



Transformer

Catalog Number


9T83C9386G15

150.0 KVA 60 HZ 3 PH 3.9 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: QL

Note: Design is based on 225.0KVA & 150C Rise 5.8% Imp.


PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 220 VOLTS (LINE-LINE)
 127 VOLTS (LINE-NEUTRAL)

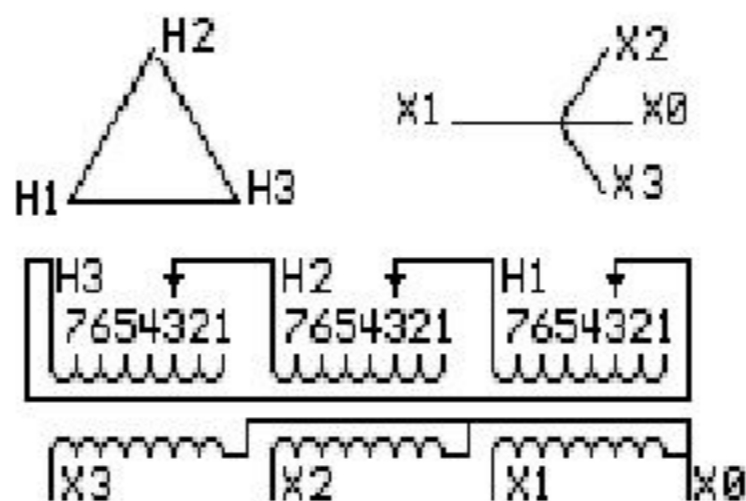

JUMPER CONNECTION

TAP	VOLTS
1	502
2	489
3	480
4	470
5	457
6	445
7	432

COIL TAP ARRANGEMENT

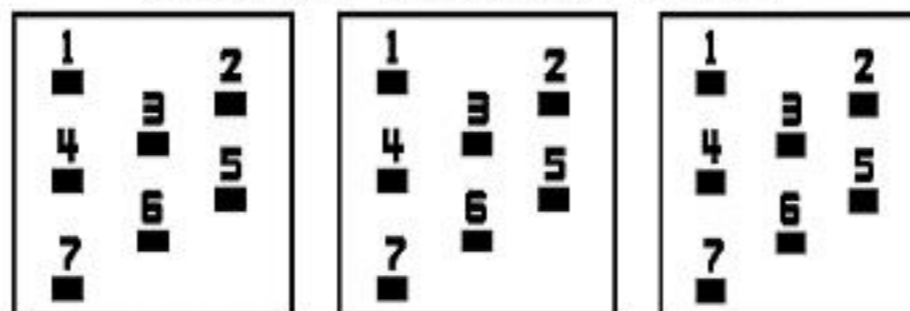

NET WGT 1700 LB 771.1 Kg

112515 N548! KV377
 47185 NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B919AAP077
Assembled in Mexico

INSPECTION & FINAL TEST
N548!