




Transformer

Catalog Number 9T83C9388G15

9Q3C300AAAZ00B2T00

300.0 KVA 60 HZ 3 PH 6.6 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: QL

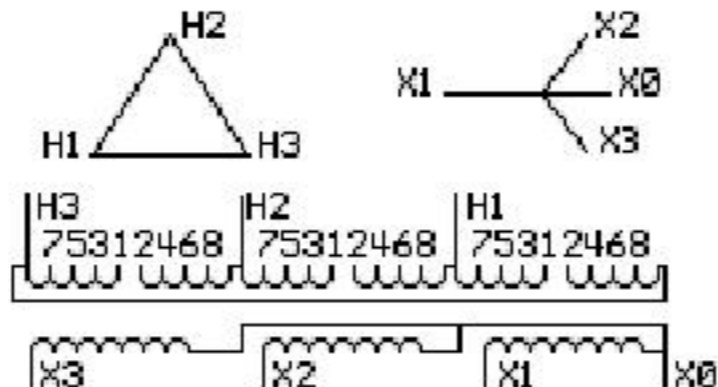


JUMPER CONNECTION

TAP	VOLTS
1-2	502
2-3	490
3-4	480
4-5	466
5-6	454
6-7	442
7-8	429

PRIMARY (H) 480 VOLTS (LINE-LINE)
 SECONDARY (X) 220 VOLTS (LINE-LINE)
 127 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

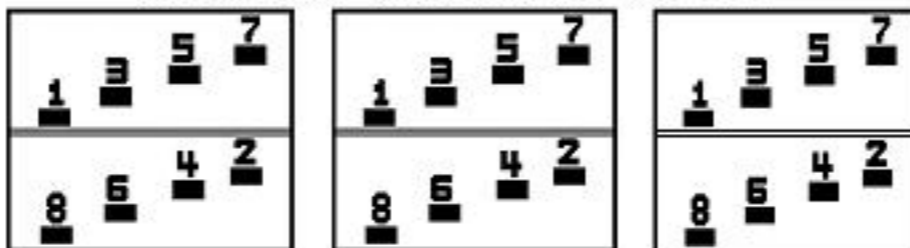

NET WGT 3150 LB 1428.8 Kg

120915 N550! YF378
 58535 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD NOT REQUIRED

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B919AAP178
 Assembled in Mexico

INSPECTION & FINAL TEST
 N550!

