




Transformer

Catalog Number

9T83C9519

500.0 KVA 60 HZ 3 PH 4.5 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

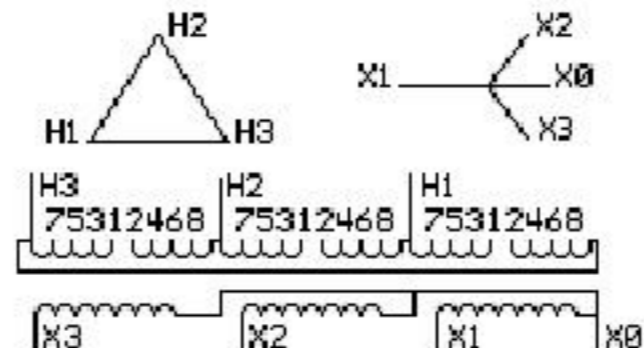


JUMPER CONNECTION

TAP	VOLTS
1-2	501
2-3	490
3-4	480
4-5	469
5-6	458
6-7	448
7-8	437

PRIMARY (H) 480 VOLTS (LINE-LINE)
 SECONDARY (X) 240 VOLTS (LINE-LINE)
 139 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

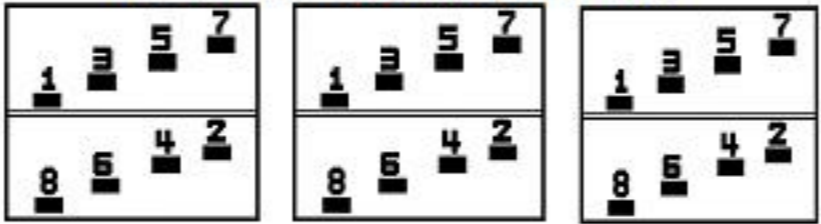

NET WGT 4050 LB 1837.1 Kg

090115 N536! YF379
 55803 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G 68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**



LISTED 769G

Outline: 3038919AAP179
 Assembled in Mexico

INSPECTION & FINAL TEST
 N536!

