



Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER


Catalog Number

9T83C9549G51

400.0 KVA 60 HZ 3 PH 3.9 % IMP

50 C AMB. 140 C RISE 220 C SYSTEM IS-19C Type: QL

NOT FOR SALE FOR USE IN THE UNITED STATES

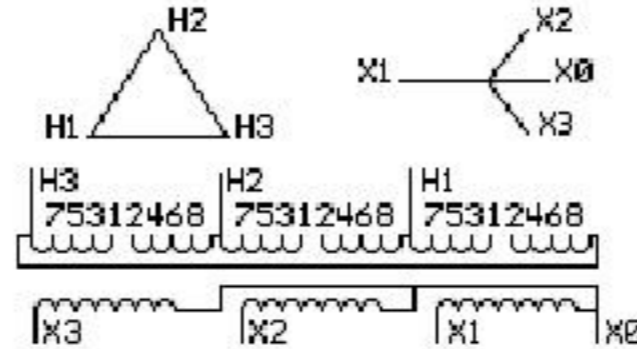


JUMPER CONNECTION

TAP	VOLTS
1-2	502
2-3	492
3-4	480
4-5	472
5-6	452
6-7	442
7-8	432

PRIMARY (H) 480 VOLTS (LINE-LINE)
 SECONDARY (X) 400 VOLTS (LINE-LINE)
 231 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

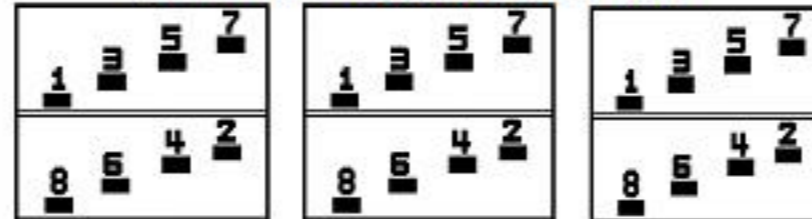

NET WGT 4050 LB 1837.1 Kg

040116 N614! YF379
60791 NOG

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N614!

