



Transformer


Catalog Number

9T83C9579

500.0 KVA 60 HZ 3 PH 3.9 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL


PRIMARY (X) 480 VOLTS (LINE-LINE)
SECONDARY (H) 575 VOLTS (LINE-LINE)

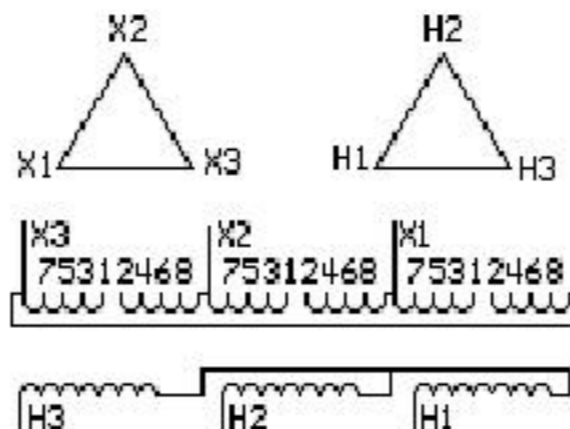

JUMPER CONNECTION

TAP	VOLTS
1-2	499
2-3	488
3-4	480
4-5	467
5-6	456
6-7	445
7-8	434

COIL TAP ARRANGEMENT

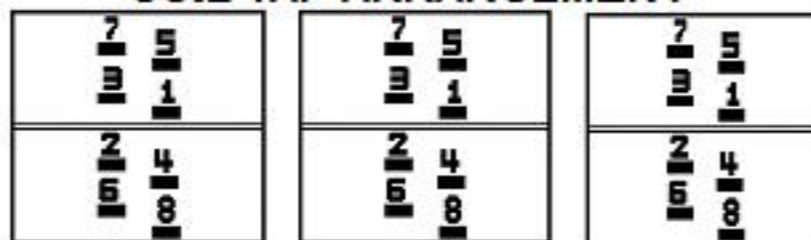

NET WGT 4050 LB 1837.1 Kg
090115 N536! YF379
56810 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G 68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N536!

