



Transformer


Catalog Number 9T83C9888G20

9Q3C300AAB00B2T30


300.0 KVA 60 HZ 3 PH 3.9 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: QL

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)

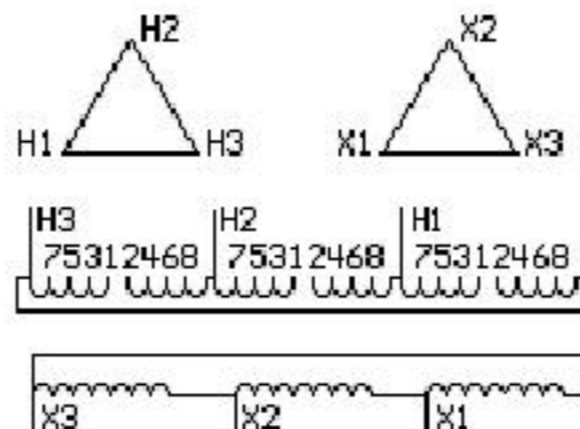

COIL TAP ARRANGEMENT

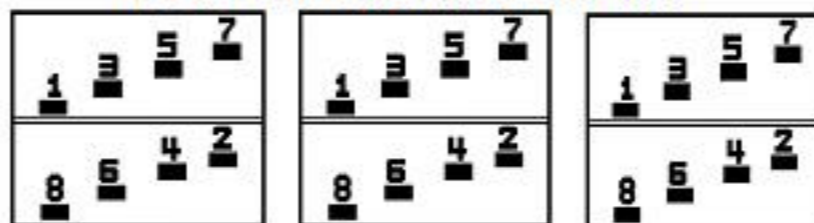

JUMPER CONNECTION

| TAP | VOLTS |
|-----|-------|
| 1-2 | 507 |
| 2-3 | 489 |
| 3-4 | 480 |
| 4-5 | 471 |
| 5-6 | 453 |
| 6-7 | 444 |
| 7-8 | 436 |

NET WGT 4050 LB 1837.1 Kg

090115 N536! YF379
55830 NOG



LISTED 769G

Outline: 3038919AAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N536!

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

