



# Transformer


Catalog Number

**9T83C9889G50**

**500.0 KVA    60 HZ    3 PH    2.9 % IMP**

40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C    Type: QL


PRIMARY (H)    480 VOLTS (LINE-LINE)  
SECONDARY (X)    240 VOLTS (LINE-LINE)

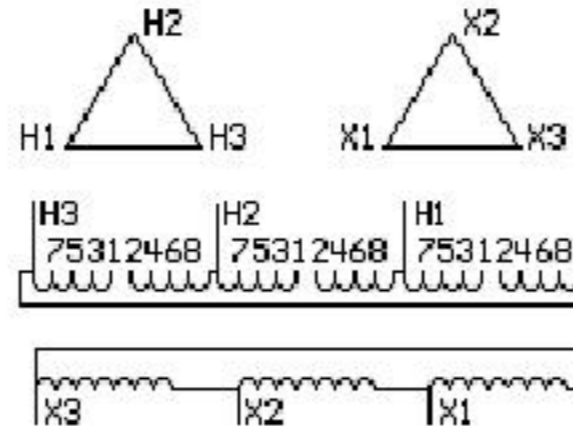

JUMPER CONNECTION

TAP	VOLTS
1-2	502
2-3	491
3-4	480
4-5	469
5-6	458
6-7	447
7-8	436

### COIL TAP ARRANGEMENT

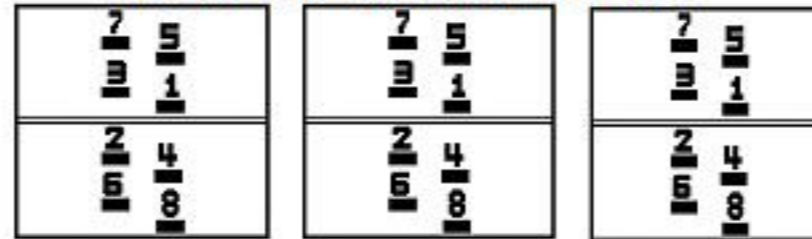

NET WGT 4050 LB    1837.1 Kg

090115

N536!

56831

NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
COPPER CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**



LISTED 769G

Outline: 3038919AAP179

Assembled in Mexico

INSPECTION & FINAL TEST

N536!