



Drive Isolation Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83K4000G21

15.0 KVA 60 HZ 3 PH 4.8 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 230 VOLTS (LINE-LINE)
133 VOLTS (LINE-NEUTRAL)

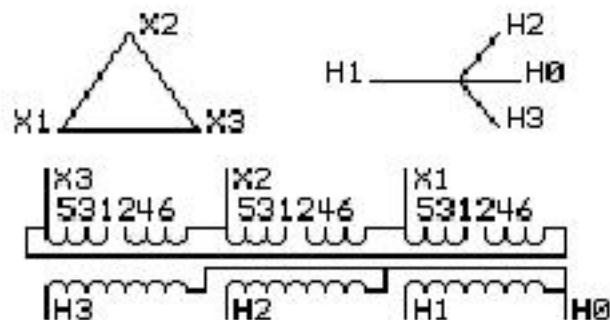

JUMPER CONNECTION


TAP	VOLTS
1-2	219
3-4	208
5-6	198

NET WGT
240 LB
108.9 Kg

60481
XV371
NOG
022916

INSPECTION
&
FINAL TEST
N610!

COIL TAP ARRANGEMENT

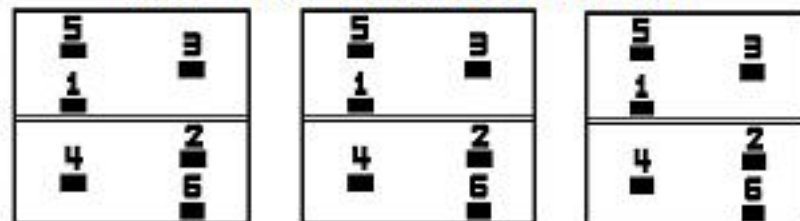

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B401CAP071

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

H3 - H2 - H1 - -
- X3 - X2 - X1


Note:

H3 - H2 - H1 -
- X3 - X2 - X1
H3 - H2 - H1 -
- X3 - X2 - X1

H0



2M000000

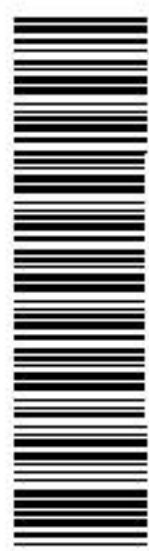

3M000000