



Transformer


Catalog Number

9T83K9899

500.0 KVA 60 HZ 3 PH 5.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL


PRIMARY (H) 600 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

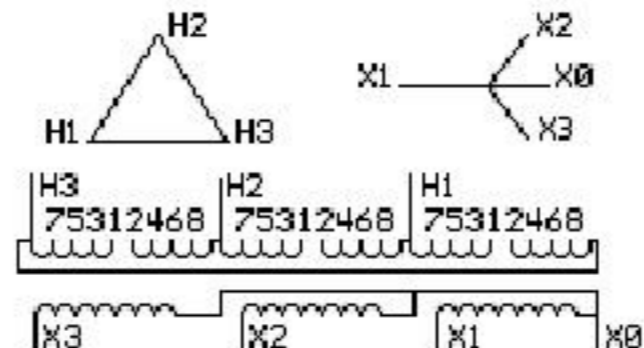

JUMPER CONNECTION

TAP	VOLTS
1-2	630
2-3	610
3-4	600
4-5	580
5-6	570
6-7	550
7-8	540

COIL TAP ARRANGEMENT

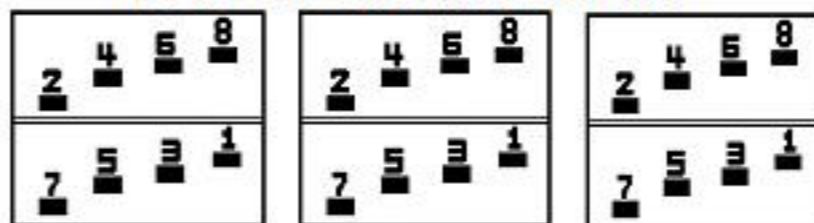

NET WGT 4050 LB 1837.1 Kg

090115

N536!

55833

NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 3038919CAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N536!

