



# Transformer




\*1M0000000\*

Catalog Number **9Q3A112AEAP00A5T00** Type QL  
9T83S3655

**112.5 KVA 60 HZ 3 PH 6.4 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 240 VOLTS (LINE-LINE)  
SECONDARY (H) 480 VOLTS (LINE-LINE)

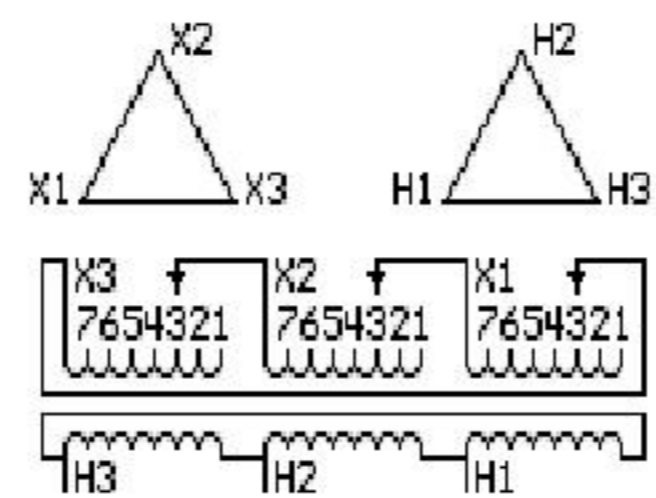


JUMPER CONNECTION	
TAP	VOLTS
1	250
2	245
3	240
4	235
5	230
6	220
7	215

NET WGT  
765 LB  
347.0 Kg  
  
58054  
XV375  
NOG  
102115

INSPECTION  
&  
FINAL TEST  
N543!

### COIL TAP ARRANGEMENT

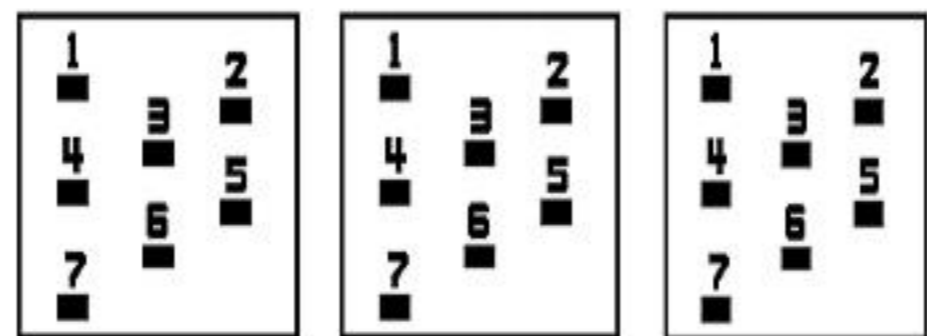

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18S4317G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline: 303B401SAP075  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

H3 - H2 - H1 - -  
- X3 - X2 - X1

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note: Standard

H1 - X1  
H2 - X2  
H3 - X3  
H1 - X1  
H2 - X2  
H3 - X3  
H3 - X3  
H3 - X3

\*2M0000000\*

\*3M0000000\*