



Transformer


Catalog Number 9T83W3877G15

225.0 KVA 60 HZ 3 PH 5.2 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: QL


Note: Design is based on 300.0KVA & 150C Rise 6.9% Imp.

PRIMARY (H)	480 VOLTS (LINE-LINE)
SECONDARY (X)	208 VOLTS (LINE-LINE)
	120 VOLTS (LINE-NEUTRAL)

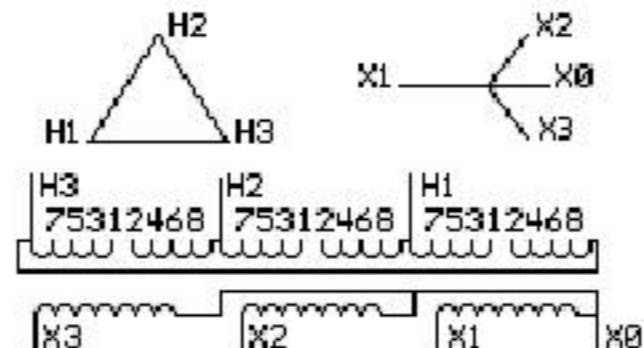

JUMPER CONNECTION	
TAP	VOLTS
1-2	506
2-3	493
3-4	480
4-5	468
5-6	455
6-7	442
7-8	430

COIL TAP ARRANGEMENT

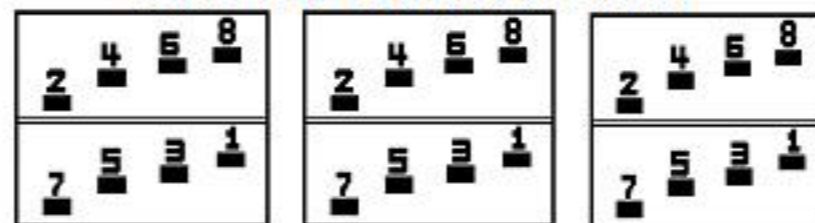

NET WGT 1470 LB 666.8 Kg

081715	N534!	L38AA
	55562	NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18W4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 303B912MWP178
Assembled in Mexico

INSPECTION & FINAL TEST
N534!

