



# Transformer


Catalog Number 9T83W3878

**300.0 KVA    60 HZ    3 PH    6.9 % IMP**

40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C    Type: QL

Note: Design is based on 300.0KVA & 150C Rise 6.9% Imp.


PRIMARY (H)	480 VOLTS (LINE-LINE)
SECONDARY (X)	208 VOLTS (LINE-LINE)
	120 VOLTS (LINE-NEUTRAL)

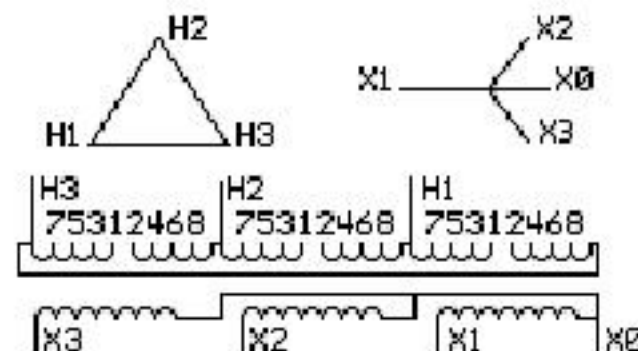

### JUMPER CONNECTION

TAP	VOLTS
1-2	506
2-3	493
3-4	480
4-5	468
5-6	455
6-7	442
7-8	430

### COIL TAP ARRANGEMENT

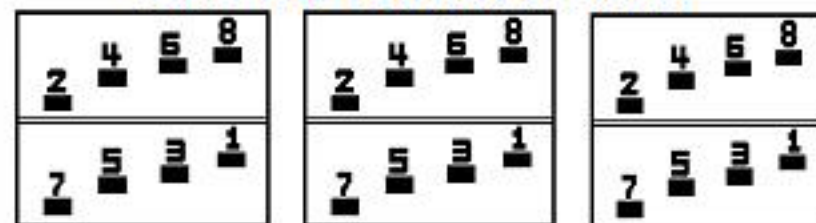

NET WGT 1470 LB    666.8 Kg

081715	N534!	L38AA
	55562	NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18W4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**



Outline: 303B912MWP178  
Assembled in Mexico

INSPECTION & FINAL TEST  
N534!

