



Transformer


Catalog Number 9T83W3889

500.0 KVA 60 HZ 3 PH 4.8 % IMP


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

Note: Design is based on 500.0KVA & 150C Rise 4.8% Imp.

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 240 VOLTS (LINE-LINE)

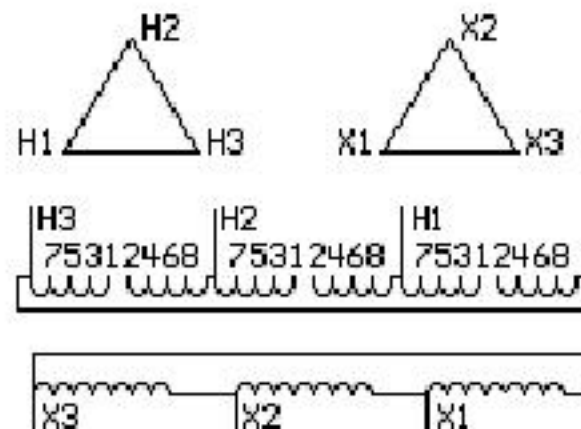

COIL TAP ARRANGEMENT

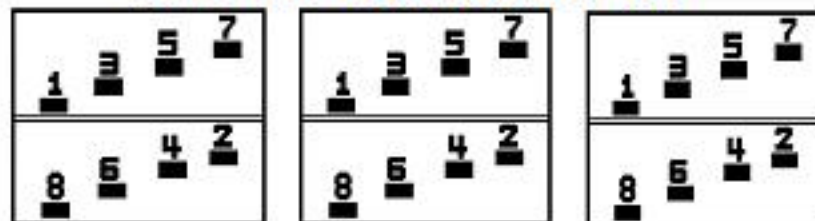

JUMPER CONNECTION	
TAP	VOLTS
1-2	502
2-3	491
3-4	480
4-5	469
5-6	458
6-7	447
7-8	436

NET WGT 3400 LB 1542.2 Kg

090315 N536! YF379
49259 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



LISTED 769G

Outline: 3038919AAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N536!

