



Core & Coil Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M0000000

X1

Catalog Number


Type QL-C

9T84C2570

15.0 KVA 60 HZ 1 PH 3.4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

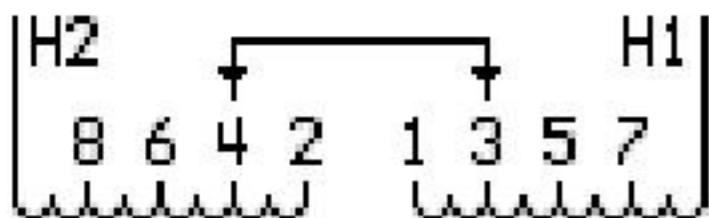


PRIMARY LINES ON H1-H2				SECONDARY LINES ON X1-X4			
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT
215	8-H1, 7-H2	431	8-7	120	X1-X3, X2-X4	240	X2-X3
229	6-H1, 5-H2	445	7-6				
240	4-H1, 3-H2	458	6-5				
251	2-H1, 1-H2	469	5-4				
		480	4-3				
		491	3-2				
		502	2-1				


NET WGT
310 LB
140.6 Kg
YF171
59140
012716

INSPECTION & FINAL TEST
N605!

COIL TAP

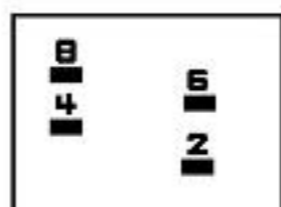

MENT

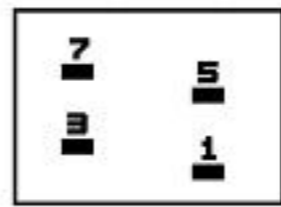

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

X3 - X4 - X2 - X1
- H2 - H1 - -

Note: Standard



2M0000000

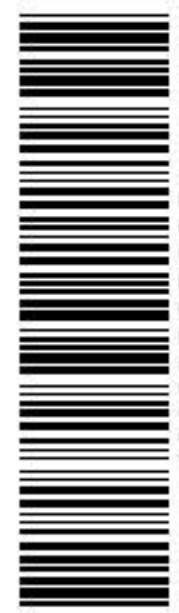

3M0000000

X2 - X2 - X4 - H1 - H2 - X3

X2 - X2 - X4 - H1 - H2 - X3