



Core & Coil Transformer




Catalog Number Type QL-C

9T84C2570G03

15.0 KVA 60 HZ 1 PH 3 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

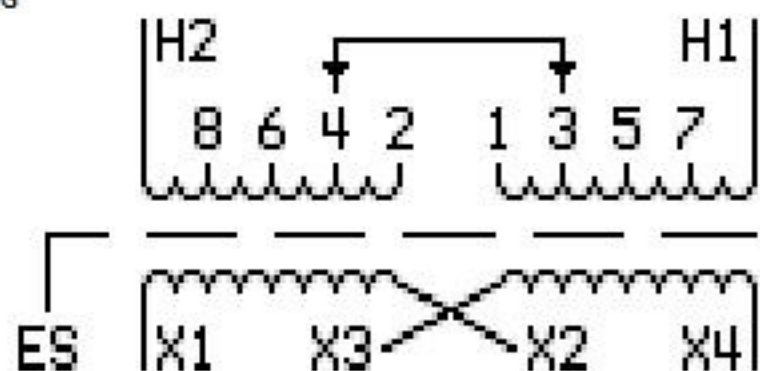

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

PRIMARY			
UOLTS	CONNECT	UOLTS	CONNECT
216	8-H1,7-H2	432	8-7
228	6-H1,5-H2	444	7-6
240	4-H1,3-H2	456	6-5
252	2-H1,1-H2	468	5-4
		480	4-3
		492	3-2

SECONDARY			
LINES ON X1-X4			
UOLTS	CONNECT		
120	X1-X3,X2-X4		
240	X2-X3		

NET WGT
310 LB

140.6 Kg

50123

070115

INSPECTION
&
FINAL TEST

N5271

COIL TAP ARRANGEMENT



LISTED 769G

Outline: 303B406AAP071 Assembled in Mexico

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1
-
X2
-
- H1
X4
- H2
X3

-
-
X2
-
X4
- H2
-
X3

