


PowerMark Gold™ Load Centers

Now with raised neutral screws for faster wiring!

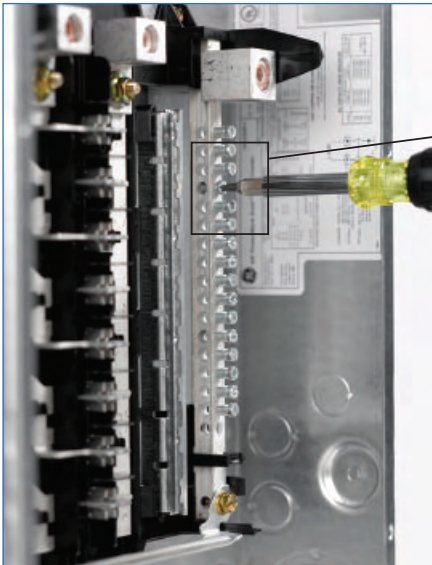

GE gives you a headstart on installation


In addition to all the other features that lower your cost by making installation faster and easier, all PowerMark Gold load centers from GE now come with neutral screws in the raised position – just insert the wire and tighten.

Full-length neutrals are easier to wire, reducing installation time and cost

Minimum 100% neutral terminations

100% rated split neutral on each side

- Exclusive GE lifetime limited warranty
- UL Listed (Panelboards No. 67)
- Suitable for use as service entrance equipment when installed in accordance with National Electrical Code®
- 60°C/75°C conductor rating

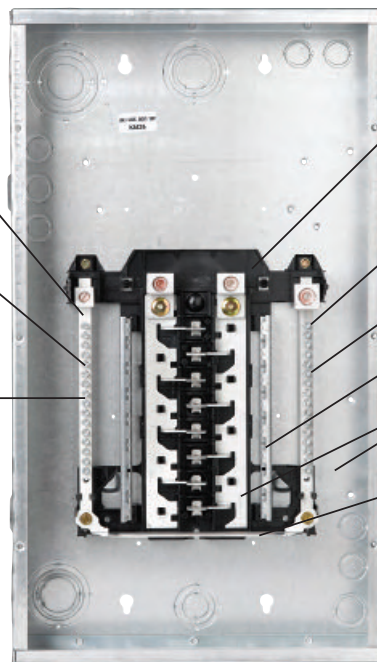

One-piece interior removes and reinstalls easily

Combination slotted/Robertson square drive screws speed wiring

All holes rated for 14-4 wire

Steel (not plastic) breaker mounting rail

Sturdy copper bus and galvanized box increase durability and reliability

Tie bar may be removed to split neutral/ground

Accepts GE Q-Line branch breakers, including GE's exclusive 1/2" THQPs



imagination at work