

# TEY D/H/L Circuit Breakers in A-Series® Panelboards

## Fact Sheet



### Reduce Your Installation Footprint

TEY D/H/L circuit breakers in A-Series Panelboards bring a more compact design to GE's fully rated (to 65kAIC) selectivity product offering. They provide full instantaneous selectivity that can be coordinated with upstream and downstream GE circuit breakers, and decrease the footprint of your installation. TEY D/H/L circuit breakers also deliver up to 65kAIC fully rated @ 480V.

### Selectivity is the Key

Selectivity offers the ability to restrict outages to the circuit or equipment affected. TEY D/H/L circuit breakers help simplify upstream selective coordination, and provide arc flash protection through current limitation. This is key for many applications such as Health Care Facilities, Elevators, Emergency Systems, and Legally Required Standby Systems such as generators, and many other critical load scenarios.

### TEY D/H/L Circuit Breakers in A-Series Panelboards Feature:

- Fits into a new A-Series Bolt-On Panelboard, Type AS
- 480V short circuit ratings of 25kA (TEYD), 35kA (TEYH), and 65kA (TEYL)
- Compact size decreases installation footprint:
  - 65kA in 1" Platform
  - True 1-, 2-, 3- Pole Construction
  - 125A Branch Mounted in A-Series
- Current limiting construction for quick response to short circuit level faults
- Allows full instantaneous selectivity that can be coordinated with upstream and downstream GE circuit breakers
- Similar to the full range of existing TEY Circuit Breaker PLUS the addition of branch mounted capability of 110A & 125A.
- Is INST (Full, .01, NEC) Selective under Record Plus® FE/FG and EntelliGuard® family
- Is Non-INST (.1, NFPA99, Traditional) Selective under Spectra® Series Circuit Breakers




## TEY D/H/L Circuit Breakers Quick Reference Guide

Circuit Breaker Type	Ampere Rating	No. Poles	Maximum Voltage Rating		UL Listed Interrupting Rating—kA										Dimensions (in)		
					Vac					Vdc							
			ac	dc	120	120/240	240	277	480	600	125	250	500	600	H	W	D
TEYD	15-70	1	277	—	65	65	—	25	—	—	—	—	—	5 1/4	1	3 1/16	
	15-125	2	480/277	—	—	65	65	—	25 <sup>1</sup>	—	—	—	—		2		
		3													3		
TEYH	15-70	1	277	—	65	65	—	35	—	—	—	—	—	5 1/4	1	3 1/16	
	15-125	2	480/277	—	—	65	65	—	35 <sup>1</sup>	—	—	—	—		2		
		3													3		
TEYL	15-70	1	277	125	100	100	—	65	—	—	15	—	—	5 1/4	1	3 1/16	
	15-125	2	480/277	250	—	100	100	—	65 <sup>1</sup>	—	42	20	—		—		2
		3									42	35	—		—		3

<sup>1</sup>480Y/277 Vac

### TEY D/H/L Catalog Number Structure

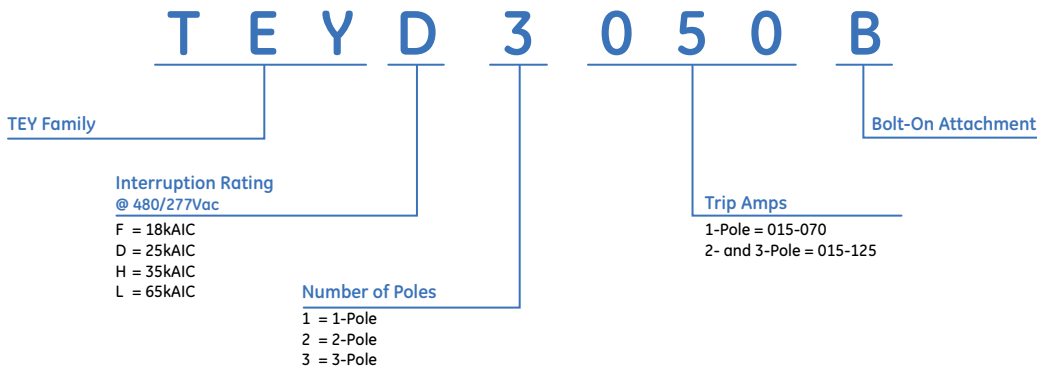

**GE**  
**Industrial Solutions**  
 41 Woodford Avenue  
 Plainville, CT 06062  
 www.geindustrial.com

© 2012 General Electric Company



A-Series®, Record Plus®, EntelliGuard® and Spectra® are trademarks of General Electric Company.

Information provided is subject to change without notice. Please verify all details with GE. All values are design or typical values when measured under laboratory conditions, and GE makes no warranty or guarantee, express or implied, that such performance will be obtained under end-use conditions.

