


Temp. 25 40 50
Shift index for long-time delay only.

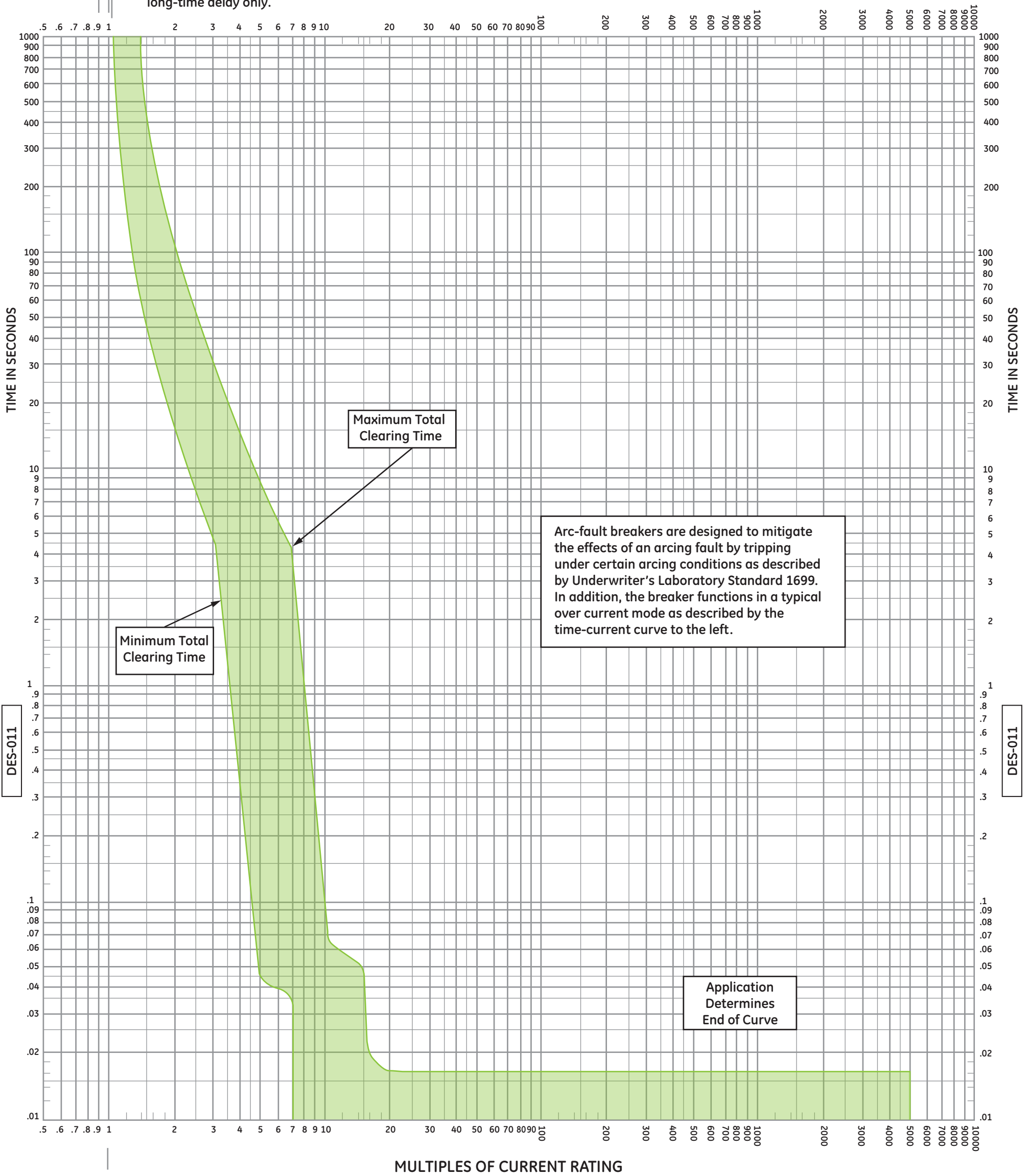

**GE Consumer & Industrial -
Electrical Distribution**

Current Ratings
15 Amperes

Voltage Ratings
1-pole - 120 Vac
2-pole - 120/240 Vac, 208Y/120 Vac

Frequency Ratings
60 Hertz

**Molded Case Circuit Breaker
with Fault Circuit Interrupter
Q Line**

Types THQL, THHQL, THQB,
THHQB AFCI (MOD C)
Long-time Delay and Instantaneous
Time-Current Curves

Curves show circuit breaker in open air, 40°C ambient,
wired with conductors of corresponding rating, no prior load.
For all other ambients, use rating shift index at top of sheet.

DES-011

Adjustments
Long-time delay thermal trip: not adjustable.
Instantaneous magnetic trip: not adjustable.