


MULTIPLES OF CURRENT SENSOR

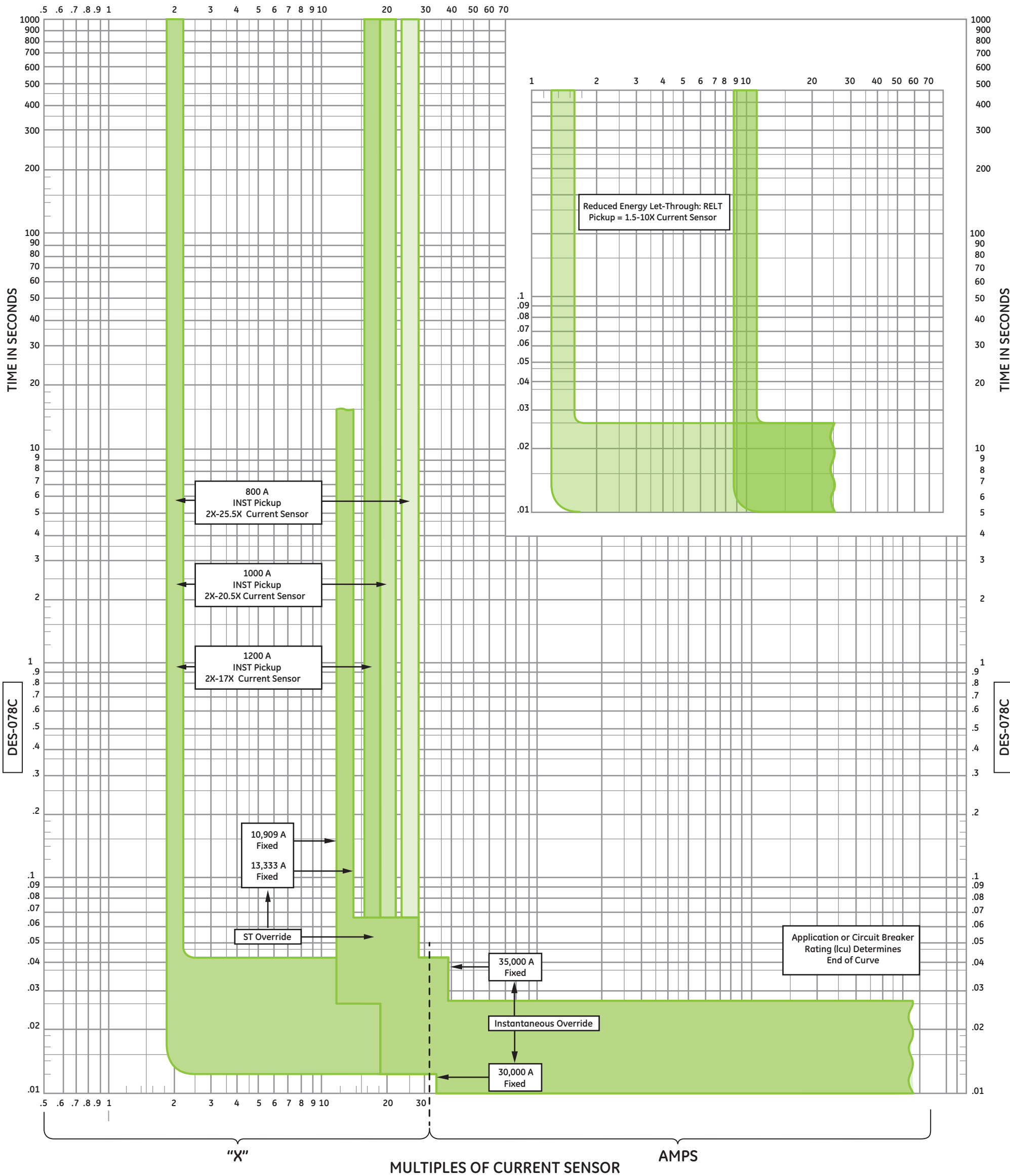

Available Ratings (Amperes)

| Type | Model | Frame | Current Sensor | Rating Plug |
|------|-------|-------|----------------|---|
| MCCB | SK | 1200 | 1200 | 1200, 1100, 1000, 900, 800, 750, 700, 600, 500, 450 |
| | | | 1000 | 1000, 900, 800, 750, 700, 600, 500, 450 |
| | | | 800 | 800, 750, 700, 600, 500, 450, 400, 350, 300 |

Voltage Rating: 480Vac or less / 60 Hz systems

Molded Case Circuit Breaker

*micro*Entelliguard®
 Extended Instantaneous (Selective)
 Spectra® K
 Instantaneous & Reduced Energy Let-through
 Instantaneous (RELT) Settings

Curves apply at 60 Hertz and from -20°C to 55°C circuit breaker ambient temperature.

DES-078C

Programmer Adjustments

- SKS and SKT models
- INST Pickup Settings (multiple of Sensor):**
 2.0 - 14.0x in increments of 0.5x
 15.0 - 19.0x in increments of 1.0x
 20.5X - 25.0x in increments of 1.5x
 25.5X
- Max Pickup Setting (multiple of Sensor):**
 800A Sensor - 25.5x
 1000A Sensor - 20.5x
 1200A Sensor - 17x
- RELT Pickup Settings (multiple of Sensor):**
 1.5 - 10.0x in increments of 0.5x