



MULTIPLE OF SENSOR

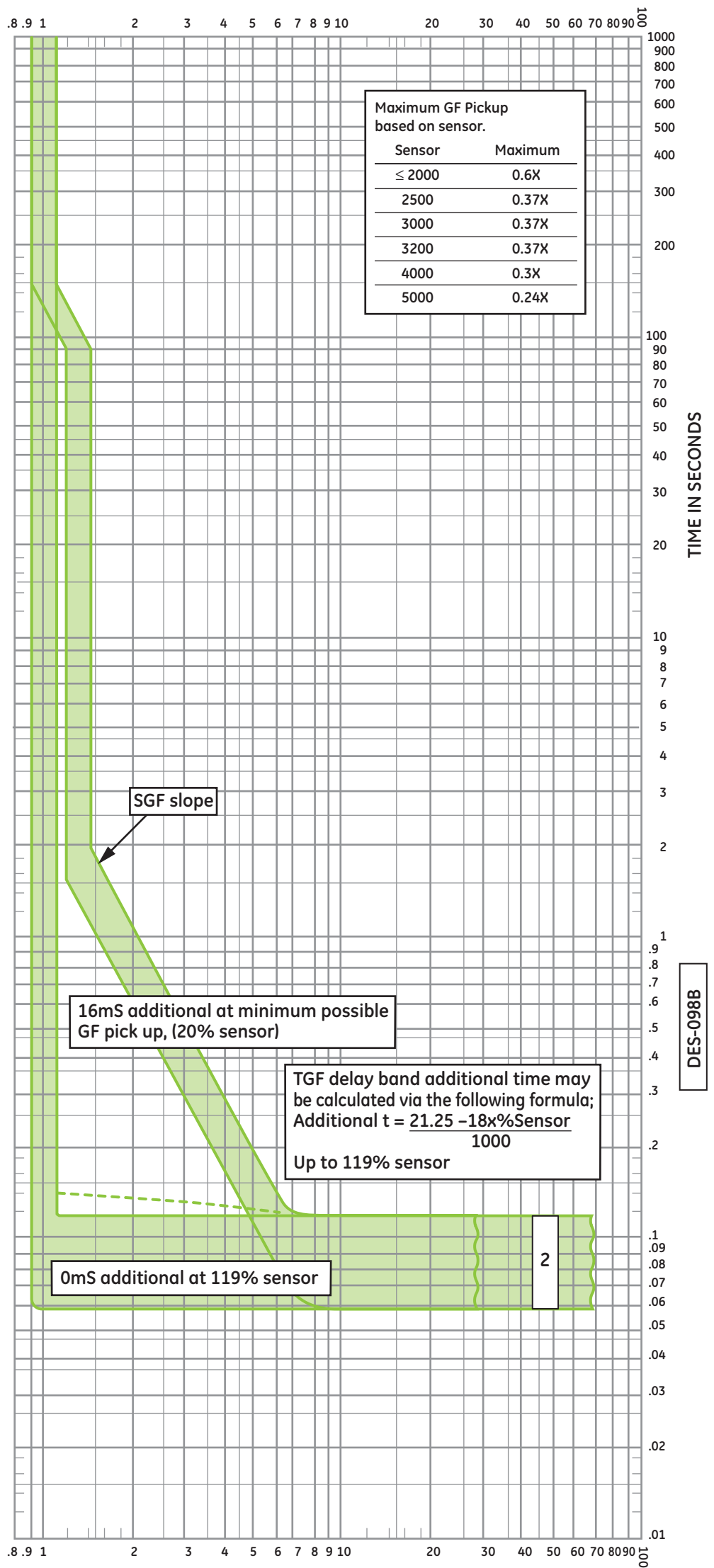

Maximum GF Pickup based on sensor.	
Sensor	Maximum
≤ 2000	0.6X
2500	0.37X
3000	0.37X
3200	0.37X
4000	0.3X
5000	0.24X

MULTIPLE OF SENSOR

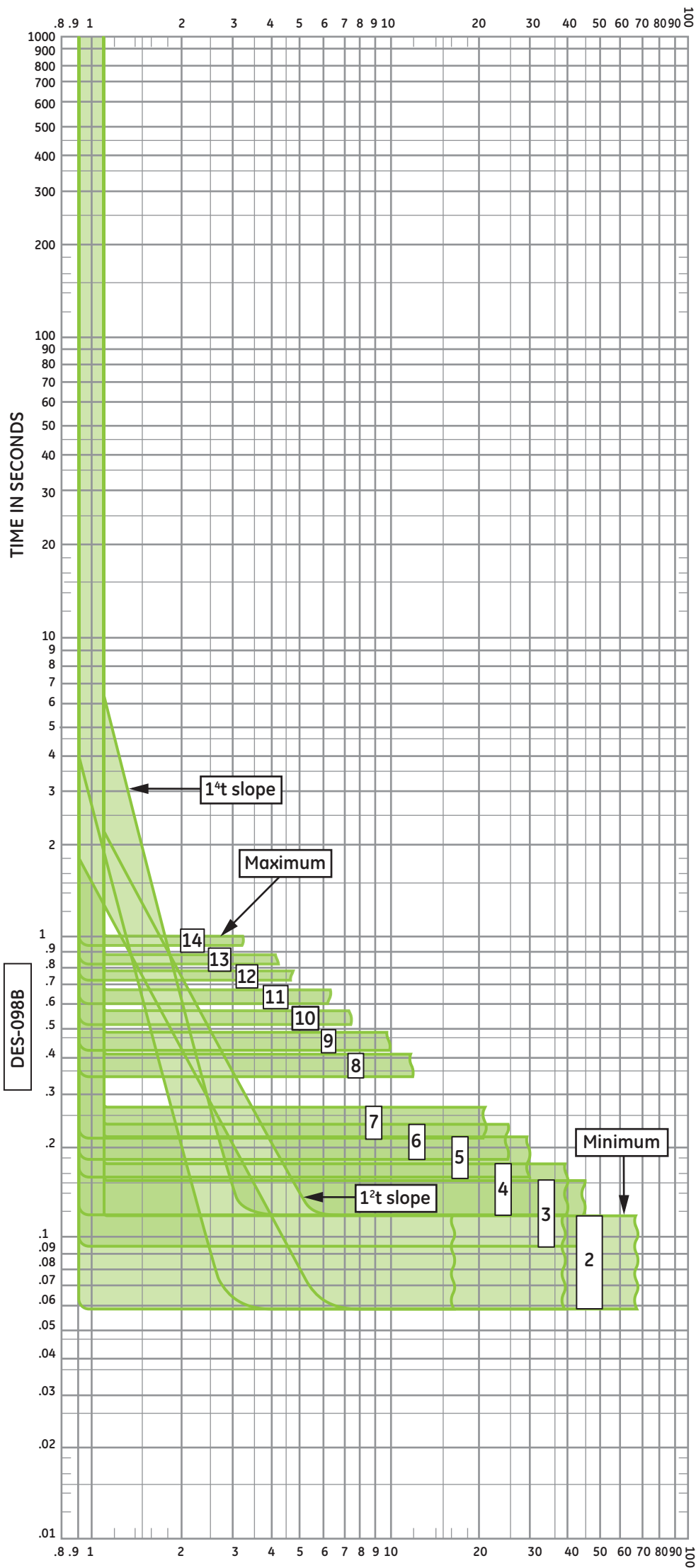

Low-Voltage Circuit Breakers

**Frames** 800-5000A AK, AKR & WavePro  
**Frames** 800-4000A PowerBreak® I & PowerBreak® II

EntelliGuard® TU Trip Unit for PowerBreak® I & II, AK & AKR, WavePro Circuit Breakers and Conversion Kits UL489 and UL1066 Stored Energy Mechanism Circuit Breakers

Ground Fault

DES-098B

**Pickup Range**  
 Minimum 0.2X Sensor  
 Maximum up to 0.6X Sensor  
 Not to exceed 1200A

All Voltages: 600 Vac and below

Curves apply at 50/60 Hertz and from -20°C to 55°C circuit breaker ambient temperature.