
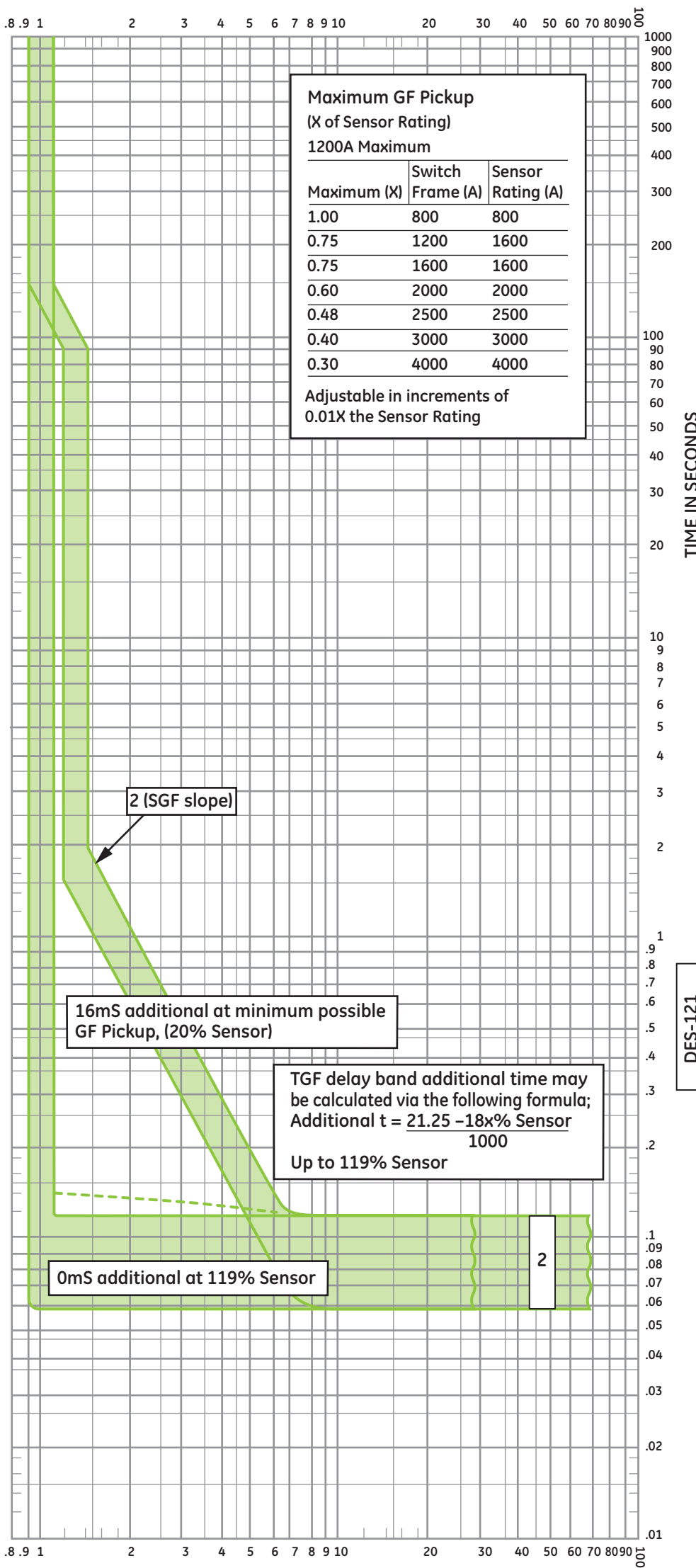


MULTIPLE OF SENSOR

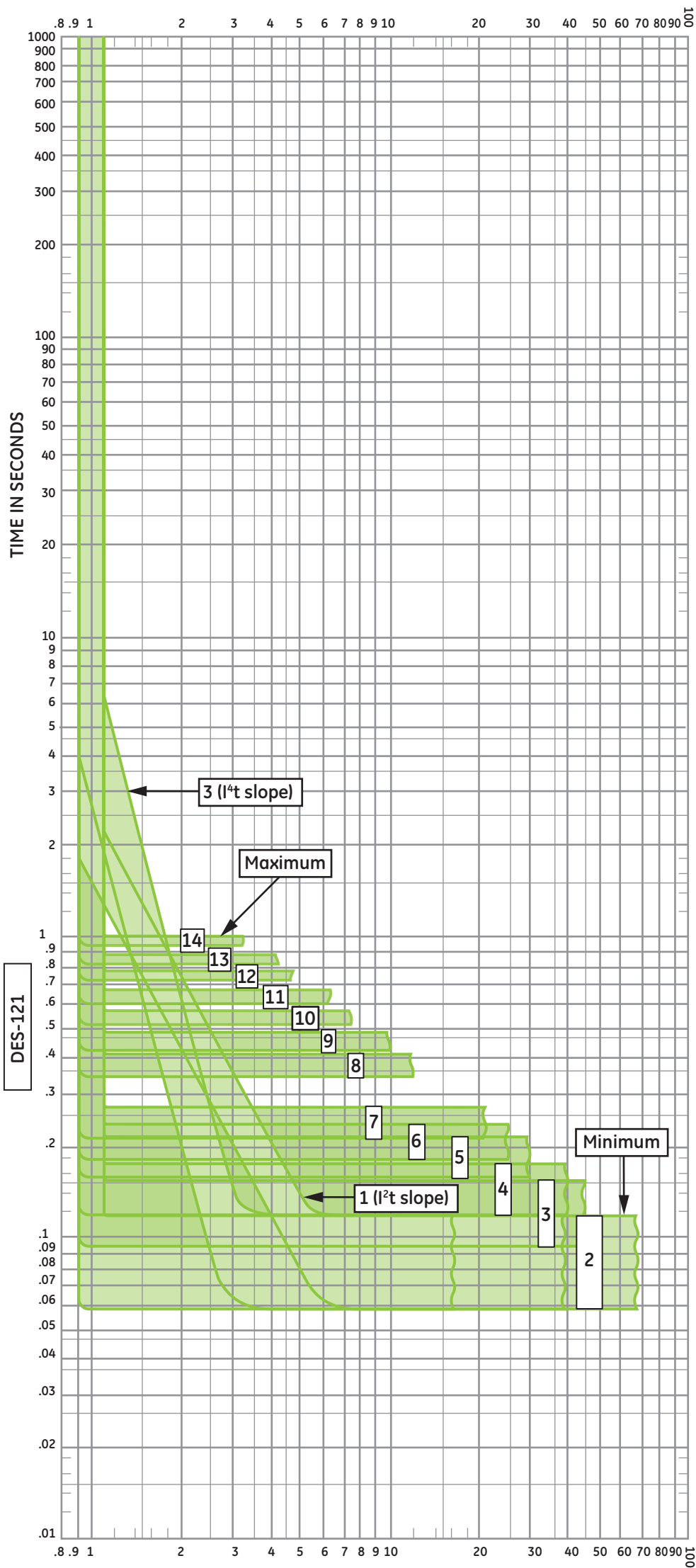

Maximum GF Pickup (X of Sensor Rating)
1200A Maximum

Maximum (X)	Switch Frame (A)	Sensor Rating (A)
1.00	800	800
0.75	1200	1600
0.75	1600	1600
0.60	2000	2000
0.48	2500	2500
0.40	3000	3000
0.30	4000	4000

Adjustable in increments of 0.01X the Sensor Rating

MULTIPLE OF SENSOR



GE Industrial Solutions

Frames 800-4000A HPC* Switches
New Generation

All Voltages: 600 Vac and below

Fusible Switches

EntelliGuard* Control Unit for HPC* Switches, New Generation (SHP Type)
UL977/cUL977
Fused Power Circuit Devices

Ground Fault

Curves apply at 60 Hertz and from -20°C to 55°C switch ambient temperature.

DES-121

Pickup Range
Minimum 0.2X Sensor
Maximum 1.0X-0.3X Sensor, not to exceed 1200A