


X

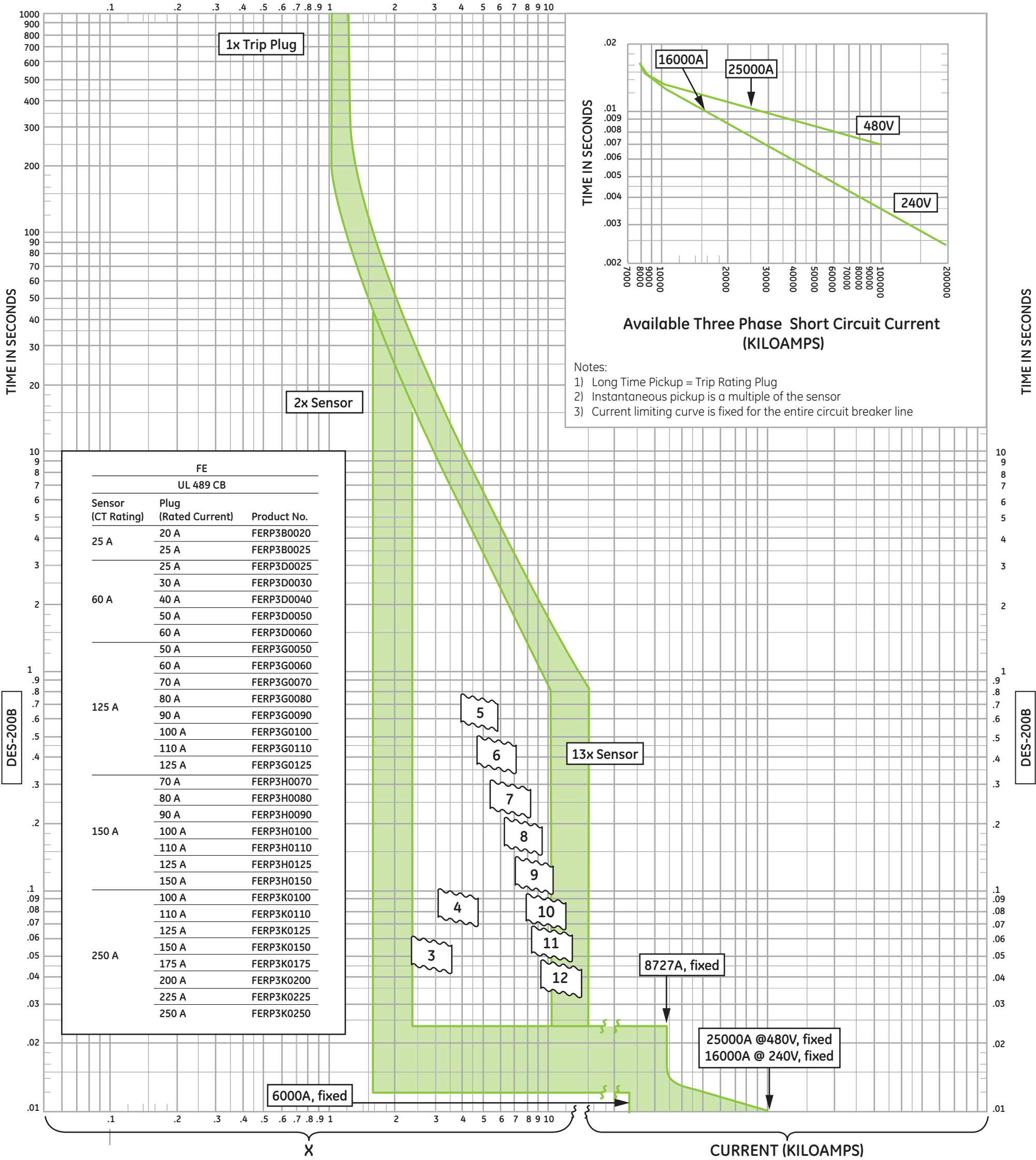

- Notes:
- 1) Long Time Pickup = Trip Rating Plug
 - 2) Instantaneous pickup is a multiple of the sensor
 - 3) Current limiting curve is fixed for the entire circuit breaker line

FE UL 489 CB		
Sensor (CT Rating)	Plug (Rated Current)	Product No.
25 A	20 A	FERP3B0020
	25 A	FERP3B0025
	25 A	FERP3D0025
60 A	30 A	FERP3D0030
	40 A	FERP3D0040
	50 A	FERP3D0050
	60 A	FERP3D0060
	50 A	FERP3G0050
	60 A	FERP3G0060
125 A	70 A	FERP3G0070
	80 A	FERP3G0080
	90 A	FERP3G0090
	100 A	FERP3G0100
	110 A	FERP3G0110
	125 A	FERP3G0125
150 A	70 A	FERP3H0070
	80 A	FERP3H0080
	90 A	FERP3H0090
	100 A	FERP3H0100
	110 A	FERP3H0110
	125 A	FERP3H0125
250 A	150 A	FERP3H0150
	100 A	FERP3K0100
	110 A	FERP3K0110
	125 A	FERP3K0125
	150 A	FERP3K0150
	175 A	FERP3K0175
	200 A	FERP3K0200
	225 A	FERP3K0225
	250 A	FERP3K0250



GE Consumer & Industrial -
Electrical Distribution

480V Max
50/60 Hz

- Curve Applies to:
- FER(2,3)4AA0025R
 - FER(2,3)4AA0060R
 - FER(2,3)4AA0125R
 - FER(2,3)4AA0150R
 - FER(2,3)4AA0250R
 - FEH(2,3)4AA0025R
 - FEH(2,3)4AA0060R
 - FEH(2,3)4AA0125R
 - FEH(2,3)4AA0150R
 - FEH(2,3)4AA0250R

Molded Case Circuit Breaker
with SMR1 Solid State Trip
Record Plus™ Type FE

DES-200B

Adjustable instantaneous 2-13x Sensor