
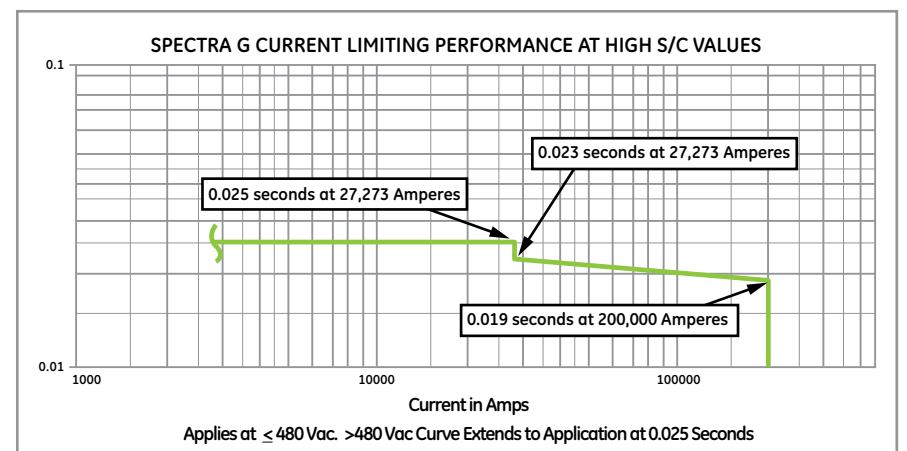
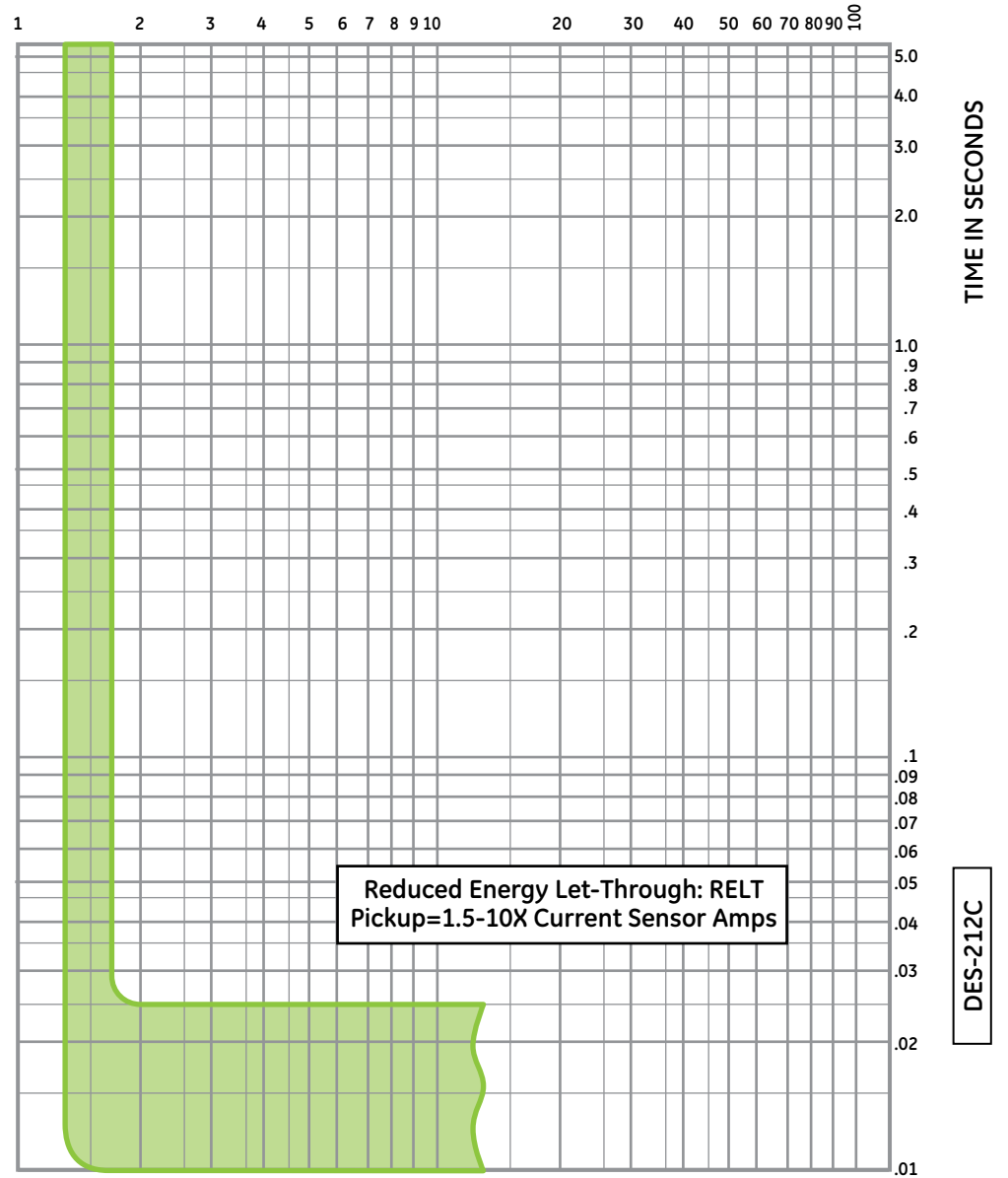


MULTIPLE OF CURRENT SENSOR AMPERES

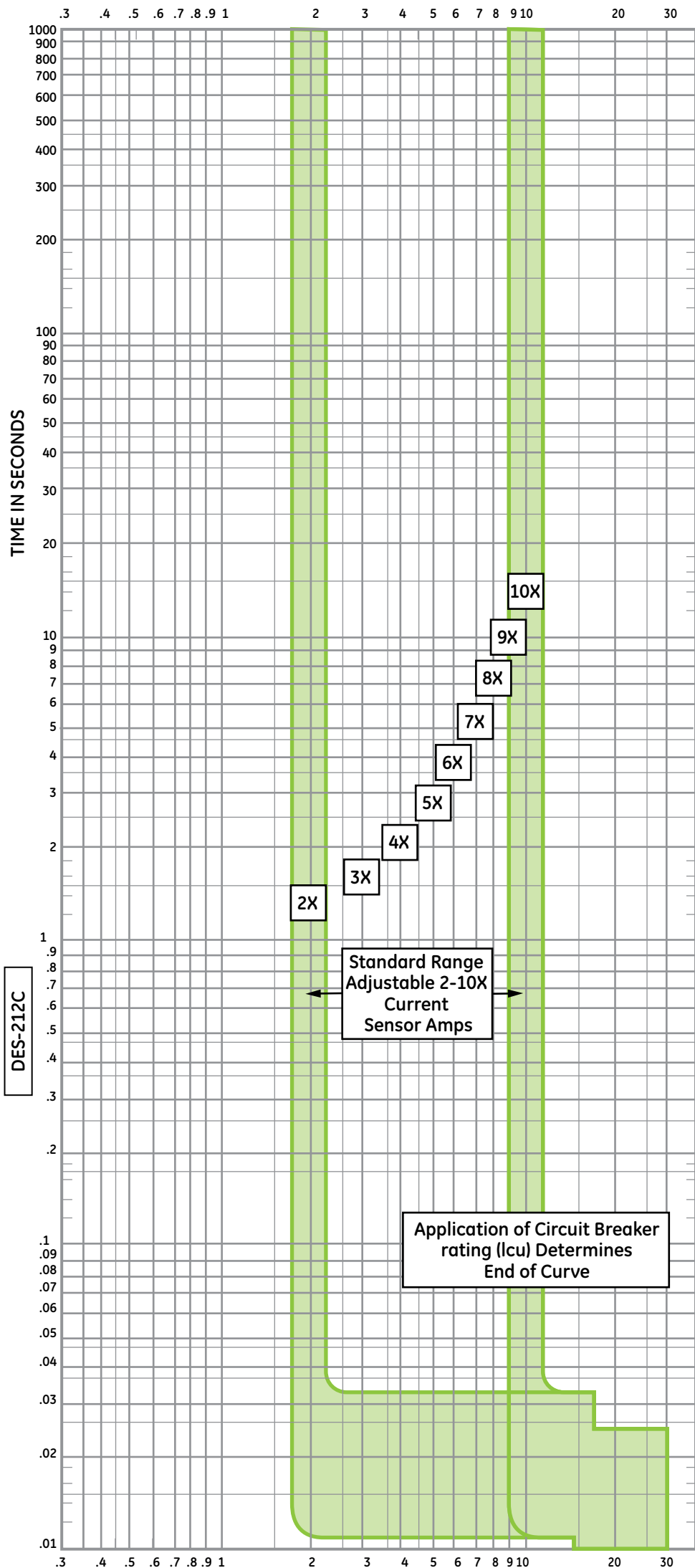

GE Consumer & Industrial - Electrical Distribution

Available Ratings (Amperes)

Type	Model	Frame	Current Sensor (S)	Rating Plug
MCCB	SG	600	150	60, 80, 100, 125, 150
			400	150, 200, 225, 250, 300, 350, 400
			600	225, 250, 300, 350, 400, 450, 500, 600

Voltage Rating: 600Vac, 50 to 60 Hz

Notes:

- Do not use on other than 50 and 60Hz systems

Molded Case Circuit Breaker

Type SG with *microEntelliGuard™* Trip Unit Time Current Curves

Instantaneous, Override (HSIOC)
Reduced Energy Let-through
Instantaneous (RELT)

Curves apply at 50 to 60 Hertz and from -20°C to 55°C breaker ambient temperature

DES-212C

Programmer Adjustments

Instantaneous Function:
Pickup Settings: 2.0 to 10.0 in increments of 0.5 multiples of current sensor amps (X)
RELT Function:
Pickup Settings: 1.5 to 10.0 in increments of 0.5 multiples of current sensor amps (X)