



Ventilation Fans, Fan Switches & Door Chimes

- Best-recognized home product brand
- Equivalent or superior to industry standard products
- Contemporary design
- Energy Star® rated fans 

- Full 1-year parts warranty
- Order with other GE products for easy minimums
- New decorative collection now available



Fan Only - Basic, Ultra Quiet, Silent

Fan Type	Style	Effective Square Feet	Sones*	Air Flow (CFM)*	Catalog Number	List Price, GO-132F
Fan Only	Basic	60	3	50	BF60CPA	\$45.50
Fan Only	Basic	85	5	70	BF85A	\$72.00
Fan Only	Basic	145	4	120	BF150A	\$177.00
Fan Only ¹	Ultra Quiet	60	0.5	50	BF50UQ	\$413.00
Fan Only ¹	Ultra Quiet	100	1.5	80	BF80UQ	\$247.50
Fan Only ¹	Ultra Quiet	125	2	110	BF110UQ	\$351.50
Fan Only ¹	Silent	100	1	80	BF80S	\$327.00
Fan Only	Wall Fan	210	6.5	180	WF180	\$300.00
Fan Only	Easy Mount	60	0.5	50	BF50EM	\$154.00
Fan Only	Easy Mount	125	3.5	100	BF125EM	\$175.00

¹Energy Star Rated



BF60CPA, BF85A
BF150A



BF50UQ, BF80UQ
BF110UQ, BF80S



WF180



BF50EM, BF125EM

Fan with Lights & Heaters

Fan Type	Style	Effective Square Feet	Sones*	Air Flow (CFM)*	Catalog Number	List Price, GO-132F
Fan & Light	Basic	85	4	70	BFL85	\$149.52
Fan & Light	Ultra Quiet	60	3	50	BFL60UQ	\$115.00
Fan & Light ¹	Ultra Quiet	100	1	80	BFL80UQ	\$603.00
Fan & Light	Ultra Quiet	125	2.5	100	BFL125UQ	\$366.24
Fan & Light	Round with Nightlight	125	3.5	100	BFL125RNL	\$300.00
Fan, Light & Heater	Lexan Lens	85	3.5	70	BFLH85L	\$275.00
Fan, Light & Heater	Single Bulb Heater	85	3.5	70	BH70SB	\$152.75
Fan, Light & Heater	Dual Bulb Heater	85	3.5	70	BH85DB	\$191.75

¹Energy Star Rated



BFL85, BFL60UQ



BFL80UQ, BFL125UQ



BFL125RNL



BFLH85L



BH70SB



BH85DB

Decorative Fan

Fan Type	Style	Effective Square Feet	Sones*	Air Flow (CFM)*	Catalog Number	List Price, GO-132F
Fan & Light	Decorative	85	4	70	BFL85DRN	\$233.75
Fan & Light	Decorative	85	4	70	BFL85DRWAF	\$275.00
Fan & Light	Decorative	85	2.5	70	BFL85ADW	\$290.00
Fan & Light	Decorative	85	4	70	BFL85DRRB	\$275.00
Fan & Light	Decorative	85	4	70	BFL85RCB	\$233.75
Fan & Light	Decorative	85	4	70	BFL85DRSB	\$331.00
Fan & Light	Decorative	85	4	70	BFL85SLW	\$290.00
Fan & Light	Decorative	85	4	70	BFL85SLN	\$290.00
Fan & Light	Decorative	85	2.5	70	BFL85SNS	\$290.00



BFL85DRN



BFL85DRWAF



BFL85DRSB



BFL85ADW



BFL85DRRB



BFL85SNS



BFL85RCB



BFL85SLW, BFL85SLN

Notes:

***Sound Level (Sones)** - For quieter operation, choose a lower sone number. Sones are units of loudness measured by a combination of laboratory decibel readings and the way people sense sound.

***Air Movement (CFM)** - For more air movement, choose a fan with a higher CFM number. The CFM measures how much air is exchanged in one minute.

*Information provided is subject to change without notice. Please verify all details with GE. All values are design or typical values when measured under laboratory conditions, and GE makes no warranty or guarantee, express or implied, that such performance will be obtained under end-use conditions.



Attention Contractors - Quickly Install GE Easy Mount Ventilation Fan



1

Attach easy mount bracket to ceiling joists.



2

Snap in fan housing.



3

Connect wiring and ducting.



BF50EM, BF125EM

Ventilation Fan Contractor Pack - Separate Fan & Housing Packs

Product Description	Quantity	Weight (Lbs.)	Carton Dimensions (inches)	Catalog Number	List Price, GO-132F
BF60CPA Fan Only	6	14	22.0 x 10.5 x 10.5	BF506PK	\$29.50 ea.
BF85A Fan Only	6	14	22.0 x 10.5 x 10.5	BF706PK	\$56.00 ea.
BFL50UQ Fan Only	4	14.75	22.0 x 11.5 x 14.5	BFL50UQ4PK	\$85.00 ea.
BFL85 Fan Only	4	14.75	22.0 x 11.5 x 14.5	BFL704PK	\$118.75 ea.
BF60CPA-85A, Housing Only	6	9.5	20.5 x 11.75 x 8.25	BF50/70HSG	\$15.83 ea.
BFL60UQ-85, Housing Only	4	11.75	16.75 x 12.25 x 12.5	BFL50/70HSG	\$30.00 ea.
BF60CPA-85A, Grill Only	6	2	10.5 x 10.375 x 4	BF50G6PK	\$13.83 ea.

Fan Switches

Switch Type	Weight (Lbs.)	Carton Dimensions (inches)	Catalog Number	List Price, GO-132F
Dual	0.3	4.0 x 4.0 x 4.0	S22	\$35.00
Triple	0.3	4.0 x 4.0 x 4.0	S33	\$36.50
Quadruple	0.5	8.0 x 5.0 x 2.25	S44	\$74.50



S22




S33



S44

Door Chimes

Chime Type	Quantity	Weight (Lbs.)	Carton Dimensions (inches)	Catalog Number	List Price, GO-132F
Single Entry Lit	24	50	21.0 x 15.5 x 10.5	CL11	\$32.75
Double Entry Lit	24	50	21.0 x 15.5 x 10.6	CL22	\$38.25
Single Entry Lit, Stucco Button Only	1	0.5	5.5 x 2.25 x 10.5	CS11	\$60.00
Double Entry Lit, Stucco Button Only	1	0.5	5.5 x 2.25 x 10.5	CS22	\$69.50
Single Entry Unlit	24	50	21.0 x 15.5 x 10.5	CNL11	\$31.50
Double Entry Unlit	24	50	21.0 x 15.5 x 10.6	CNL22	\$37.00

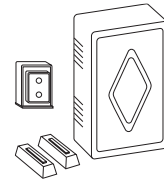

Technical Data

Catalog Number	Grill Dimensions (inches)	Housing Dimensions (inches)	Weight (Lbs.)	Carton Dimensions (inches)
BF110UQ	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	10	14-1/2 x 12 x 9
BF150A	10 x 10	9-1/8 x 9 x 5-7/8	7.25	13 x 10-1/2 x 7-1/2
BF125EM	11-2/3 x 10-3/4	9 x 8-1/2 x 4-3/4	5.2	11 x 11-3/4 x 6-1/4
BF60CPA	10 x 10	7-3/8 x 7-5/8 x 3-3/4	4.5	10 x 11 x 4-1/2
BF50EM	11-2/3 x 10-3/4	9 x 8-1/2 x 4-3/4	5.25	11 x 12 x 6-3/8
BF50UQ	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	10	14-1/8 x 11-5/8 x 9-5/8
BF85A	10 x 10	7-3/8 x 7-5/8 x 3-3/4	4.5	10 x 11 x 4-1/2
BF80S	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	10	14-1/2 x 12 x 9
BF80UQ	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	12.5	14-1/2 x 12 x 9
BFL125RNLI	13-3/4 diameter	9-1/4 x 9-1/8 x 5-7/8	12	15 x 15 x 9-3/4
BFL125UQ	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	12.5	14 x 12 x 11-3/4
BFL60UQ	10-1/2 x 11	7-3/8 x 7-5/8 x 3-3/4	5.5	13 x 11-1/2 x 9-1/2
BFL85	10-1/2 x 11	7-3/8 x 7-5/8 x 3-3/4	6	13 x 11-1/2 x 9-1/2
BFL80UQ	11 x 13-3/4	10-3/4 x 9-1/4 x 7-7/8	10	14-1/8 x 11-5/8 x 9-5/8
BFL85ADW	9 x 9	7-3/8 x 7-5/8 x 5-7/8	9.5	12-3/4 x 12-2/3 x 13
BFL85DRN	13-1/2 diameter	7-3/8 x 7-5/8 x 5-7/8	11	14 x 14 x 12-1/8
BFL85DRRB	13-1/2 diameter	7-3/8 x 7-5/8 x 5-7/8	11	14 x 14 x 12-1/8
BFL85DRSB	13-1/2 diameter	7-3/8 x 7-5/8 x 5-7/8	15	17-1/2 x 17-1/2 x 15-1/4
BFL85DRWAF	13-1/2 diameter	7-3/8 x 7-5/8 x 5-7/8	11	14 x 14 x 12-1/8
BFL85RCB	13-1/2 diameter	7-3/8 x 7-5/8 x 5-7/8	8	14 x 14 x 10-1/2
BFL85SLN	12 x 12-1/2	7-3/8 x 7-5/8 x 5-7/8	16	16 x 15-1/8 x 13-1/2
BFL85SLW	12 x 12-1/2	7-3/8 x 7-5/8 x 5-7/8	16	16 x 15-1/8 x 13-1/2
BFL85SNS	9 diameter	7-3/8 x 7-5/8 x 5-7/8	16	16 x 15-1/8 x 13-1/2
BFL85SL	17-1/8 x 9-7/8	9 x 15-3/8 x 6-1/2	15	19 x 13-1/4 x 9
BH85DB	15-3/4 x 10	7-7/8 x 14-1/2 x 5-7/8	9	18 x 13-1/4 x 7-3/4
BH70SB	10 x 10	8-1/2 x 8-1/2 x 5-7/8	7	14-1/4 x 11-1/2 x 8
WF180	11-1/2 x 11-1/2	8 x 12 x 2-1/2 cap.	13.45	10-1/4 x 15-1/4 x 10

Full one-year parts warranty. Within one year from date of purchase, GE will replace, free of charge, any part of this product that fails due to manufacturing defect. This warranty is extended to the original and any subsequent owner for products purchased for ordinary home use.