


MULTIPLES OF CURRENT RATING

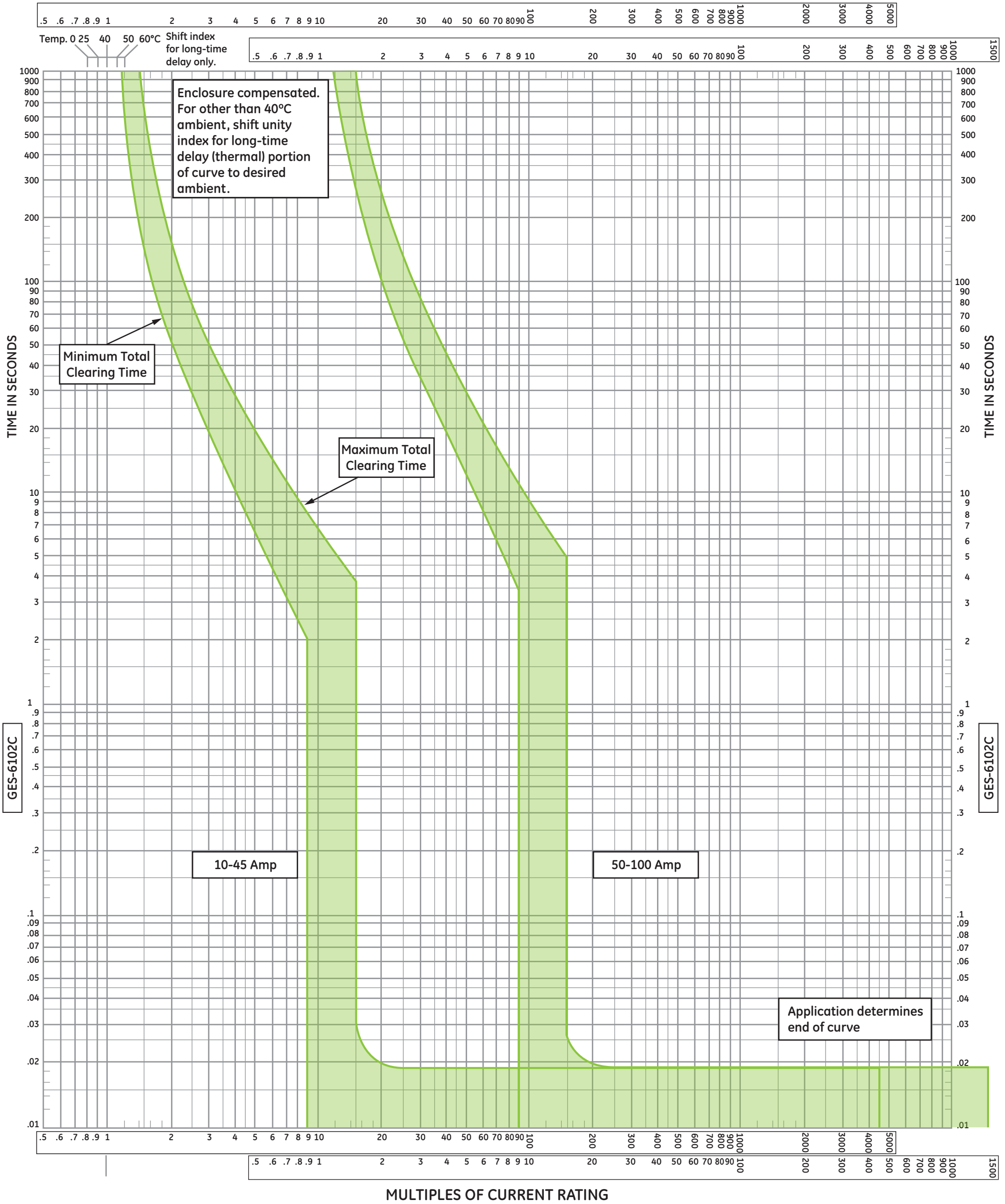

GE Consumer & Industrial -  
Electrical Distribution

**Current Ratings**

10, 15, 20, 25, 30, 35, 40, 45, 50, 60, 70,  
80, 90 and 100 Amperes

**Voltage Ratings**

277 Vac (125 Vdc)  
480 Vac (125 Vdc)

**Frequency Rating**

60 Hz

**Molded Case Circuit Breaker  
E 100 LINE**

Types TEF & THEF  
Long-time Delay and Instantaneous  
Time-current Curves

Curves show enclosure-compensated circuit breaker  
in open air, 40°C ambient, wired with conductors of  
corresponding rating, no prior load. For all other  
ambients, use rating shift index at top of sheet.


**GES-6102C**

Supersedes GES-6102B

**Adjustments**

Long-time delay thermal trip: not adjustable.  
Instantaneous magnetic trip: not adjustable.

MULTIPLES OF CURRENT RATING

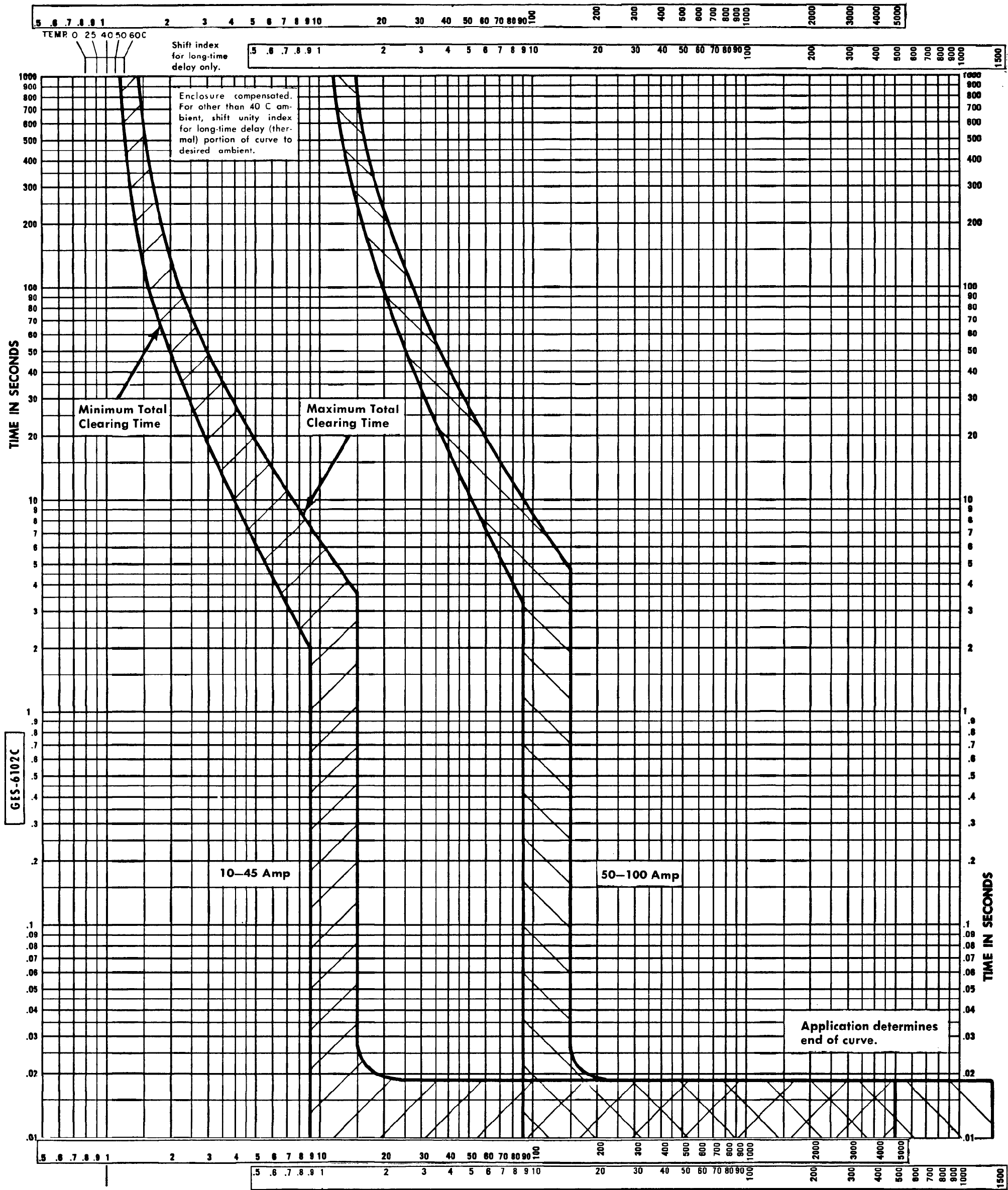

MULTIPLES OF CURRENT RATING

**GENERAL ELECTRIC**

**Current Ratings**  
10,15,20,25,30,35,40,45,50,60,70,80,  
90 and 100 amperes

**Voltage Ratings**  
277 volts ac (125 volts dc)  
480 volts ac (125 volts dc)

**Frequency Rating**  
60 Hertz

MOLDED-CASE CIRCUIT BREAKER

**E 100 LINE**

Types TEF and THEF

**Long-time Delay and Instantaneous  
Time-current Curves**

(Curves show enclosure-compensated circuit breaker in open air, 40 C ambient, wired with conductors of corresponding rating, no prior load.)  
For all other ambients, use rating shift index at top of sheet.

**GES-6102C**

Supersedes GES-6102B

**Adjustments**

Long-time delay thermal trip: not adjustable.

Instantaneous magnetic trip: not adjustable.