


MULTIPLES OF CURRENT RATING

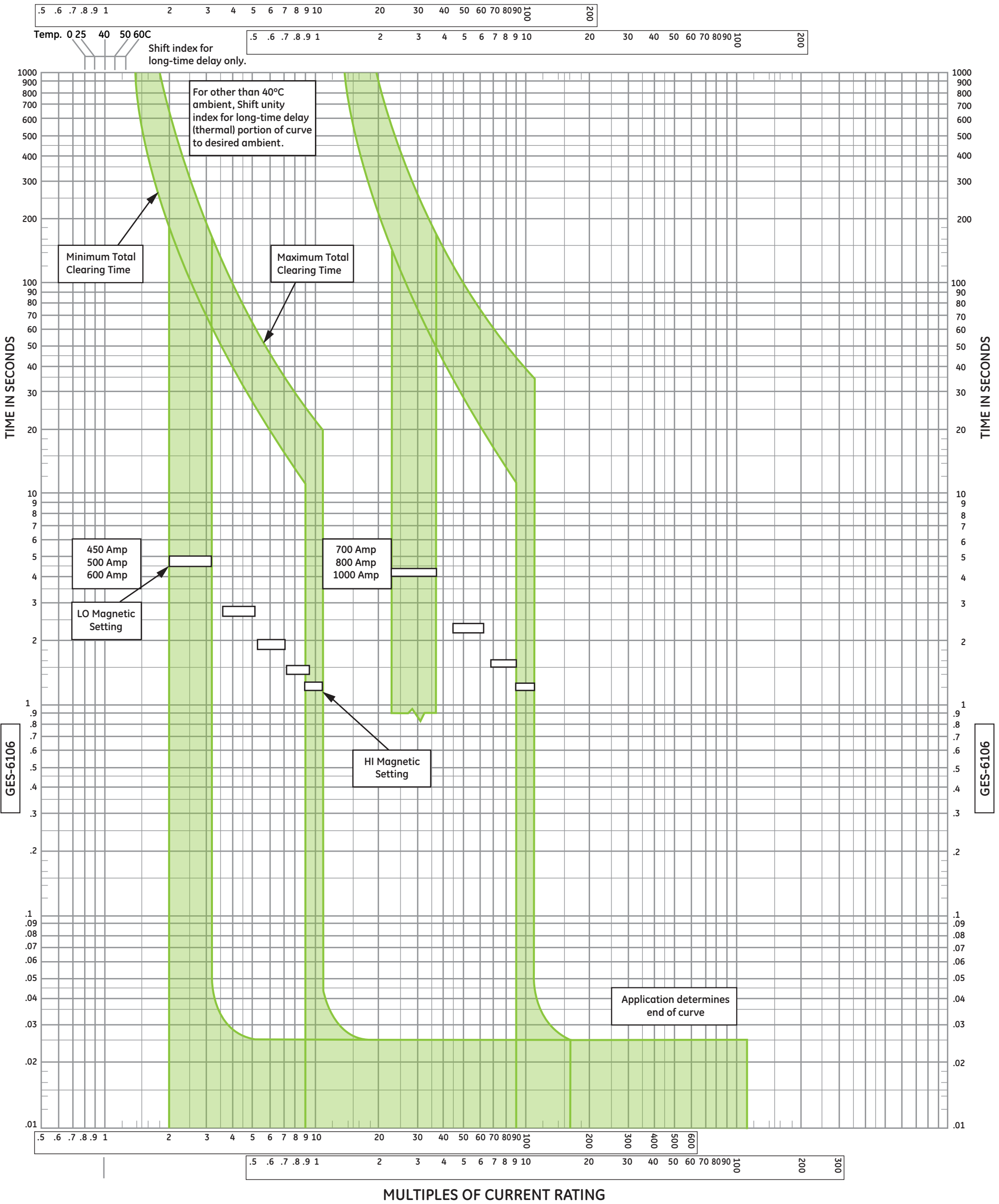

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

450, 500, 600, 700, 800 and
1000 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Ratings

Dc or 60 cycles for 450-600 Amperes
60 cycles for 700-1000 Amperes

**Molded Case Circuit Breakers
K 1000 LINE**

Types TKM & THKM (450-1000 Amperes)
Long-time Delay and Instantaneous
Time-current Curves


Curves show circuit breaker in open air, 40°C ambient,
wired with conductors of corresponding rating, no
prior load. For all other ambients, use rating
shift index at top of sheet.

GES-6106

Adjustments

Long-time delay thermal trip, not adjustable.
Instantaneous magnetic trip, five settings, factory
set on HI. Blocks show trip range at each setting.

MULTIPLES OF CURRENT RATING

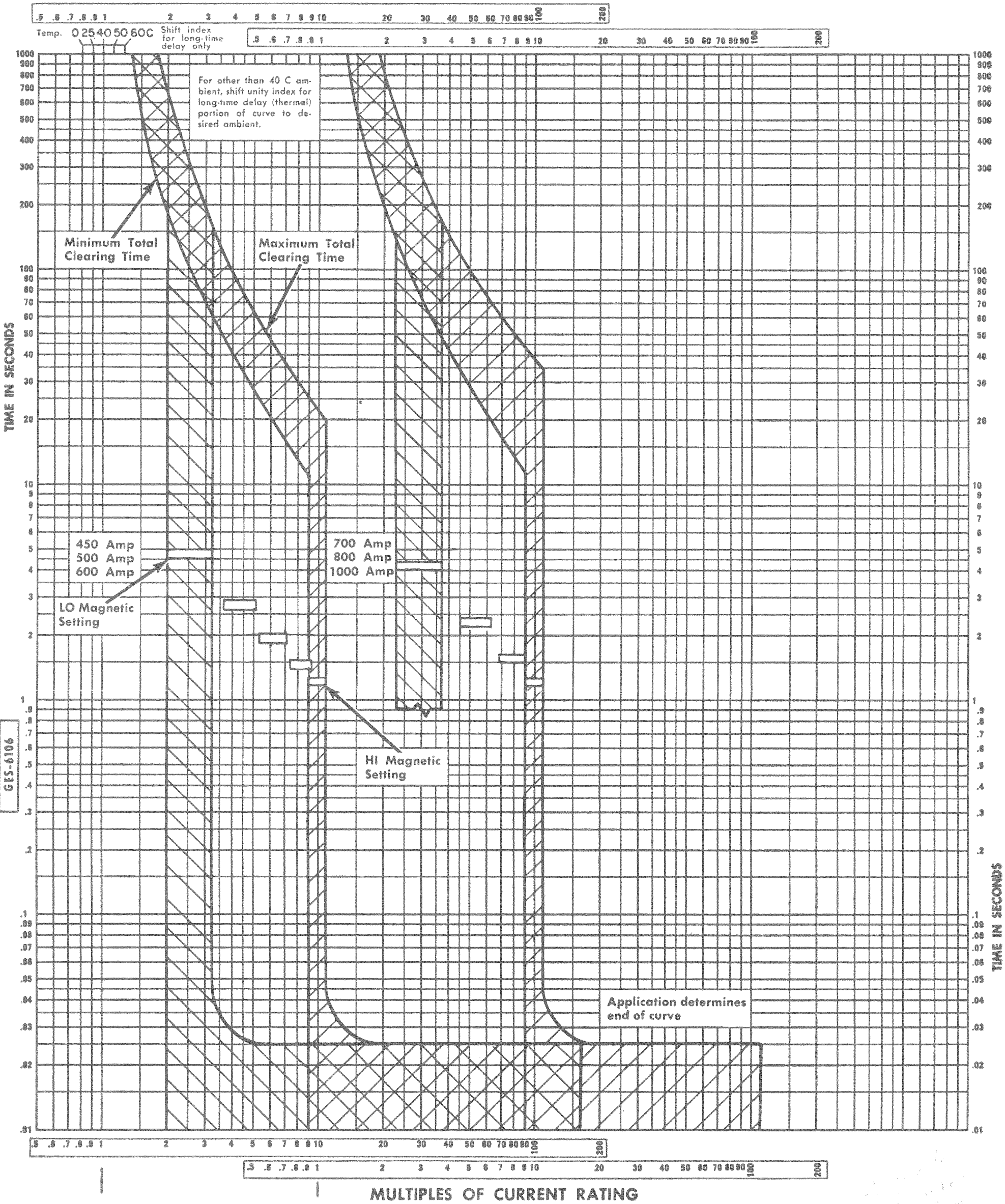

MULTIPLES OF CURRENT RATING

GENERAL ELECTRIC

Current Ratings
450, 500, 600, 700, 800 and 1000 Amperes

Voltage Ratings
600 Volts, A-c (250 Volts, D-c)

Frequency Ratings
D-c or 60 Cycles for 450-600 Amperes
60 Cycles for 700-1000 Amperes

MOLDED-CASE CIRCUIT BREAKERS
K-1000 LINE
Types TKM and THKM (450-1000 Amperes)
Long-time Delay and Instantaneous
Time-current Curves

(Curves show circuit breaker in open air, 40 C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients use rating shift index at top of sheet.)

GES-6106

Adjustments
Long-time delay thermal trip, not adjustable.
Instantaneous magnetic trip, four or five settings, factory set on HI. Blocks show trip range at each setting.