


MULTIPLES OF CURRENT RATING

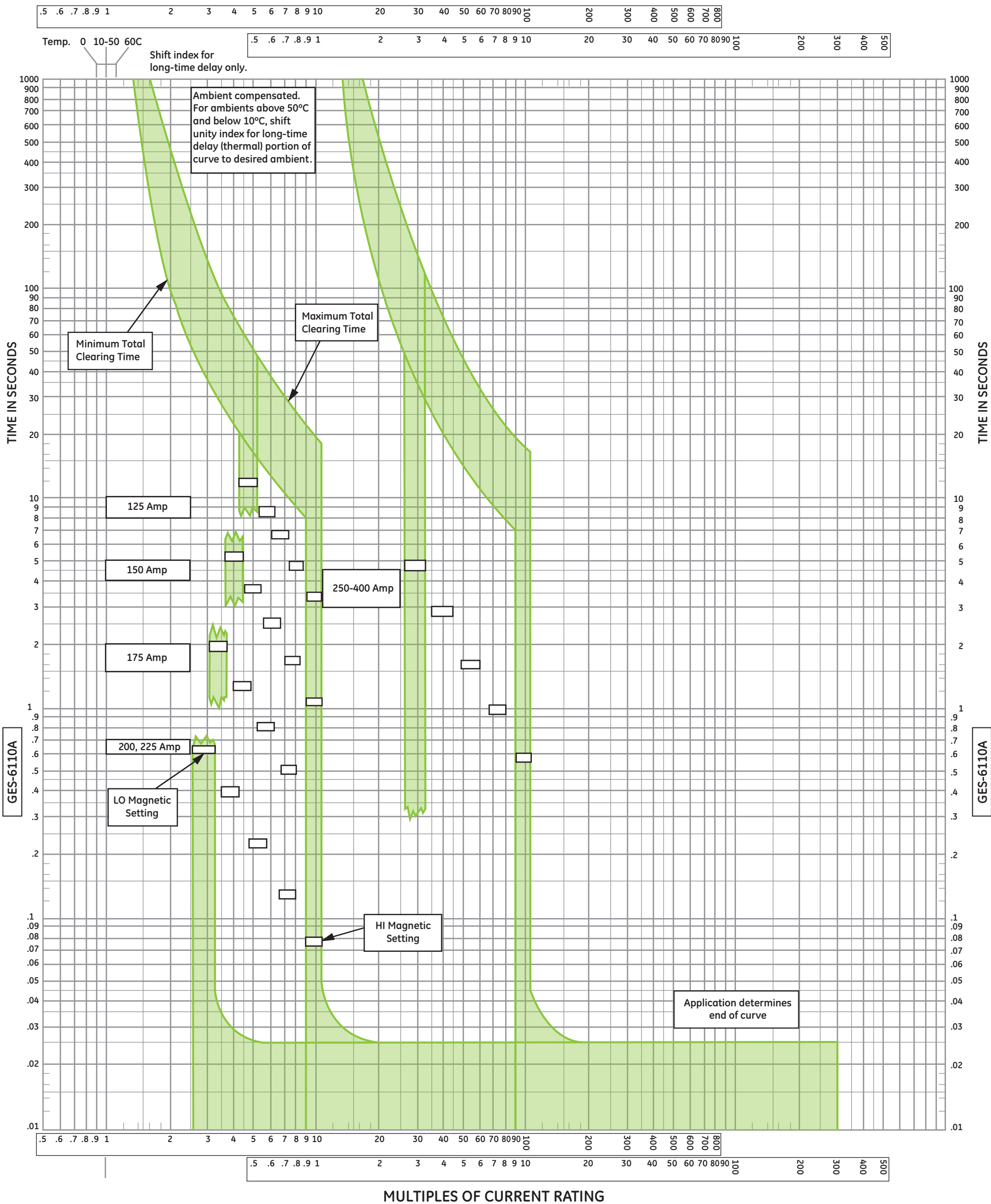

GE Consumer & Industrial -  
Electrical Distribution

**Current Ratings**

125, 150, 175, 200, 225, 250, 300, 350,  
and 400 Amperes

**Voltage Ratings**

600 Vac, 250 Vdc

**Frequency Rating**

Dc or 60 cycles

**Molded Case Circuit Breaker  
K 1200 LINE**

Types TKMA & THKMA (125–400 Amperes)  
Long-time Delay and Instantaneous  
Time-current Curves


Curves show ambient-compensated circuit breaker  
in open air, 10°C to 50°C ambient, wired with  
conductors of corresponding rating, no prior load. For  
all other ambients, use rating shift index at top of sheet.

**GES-6110A**

**Adjustments**

Long-time delay thermal trip: not adjustable.  
Instantaneous magnetic trip: continuously  
adjustable, factory set on HI.  
Blocks show trip range at marked points on  
instantaneous dials.

MULTIPLES OF CURRENT RATING

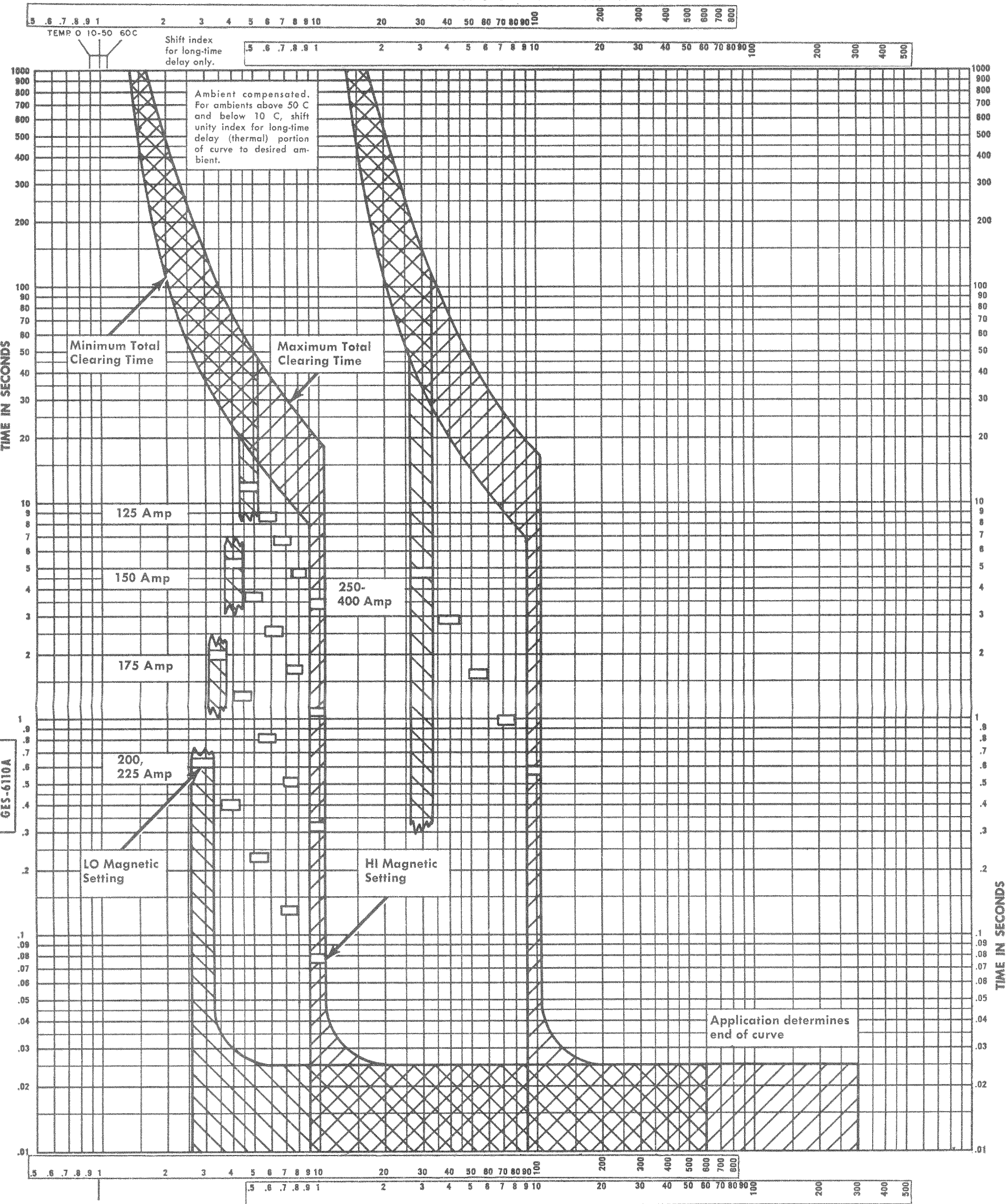

MULTIPLES OF CURRENT RATING

<p><b>GENERAL ELECTRIC</b></p> <p><b>Current Ratings</b> 125, 150, 175, 200, 225, 250, 300, 350 and 400 amperes</p> <p><b>Voltage Ratings</b> 600 volts a-c (250 volts d-c)</p> <p><b>Frequency Ratings</b> D-c or 60 cycles</p>	<p><b>MOLDED-CASE CIRCUIT BREAKER</b></p> <p><b>K-1200 LINE</b></p> <p><b>Types TKMA and THKMA (125—400 Amperes)</b></p> <p><b>Long-time Delay and Instantaneous Time-current Curves</b></p> <p>(Curves show ambient-compensated circuit breaker in open air, 10 to 50 C ambient, wired with conductors of corresponding rating, no prior load. For all other ambients, use rating shift index at top of sheet.)</p>	<p><b>GES-6110A</b></p> <p>Supersedes GES-6110</p> <p><b>Adjustments</b></p> <p>Long-time delay thermal trip: not adjustable. Instantaneous magnetic trip: continuously adjustable, factory set on HI. Blocks show trip range at marked points on instantaneous dials.</p>
--	--	--