


MULTIPLES OF CURRENT RATING

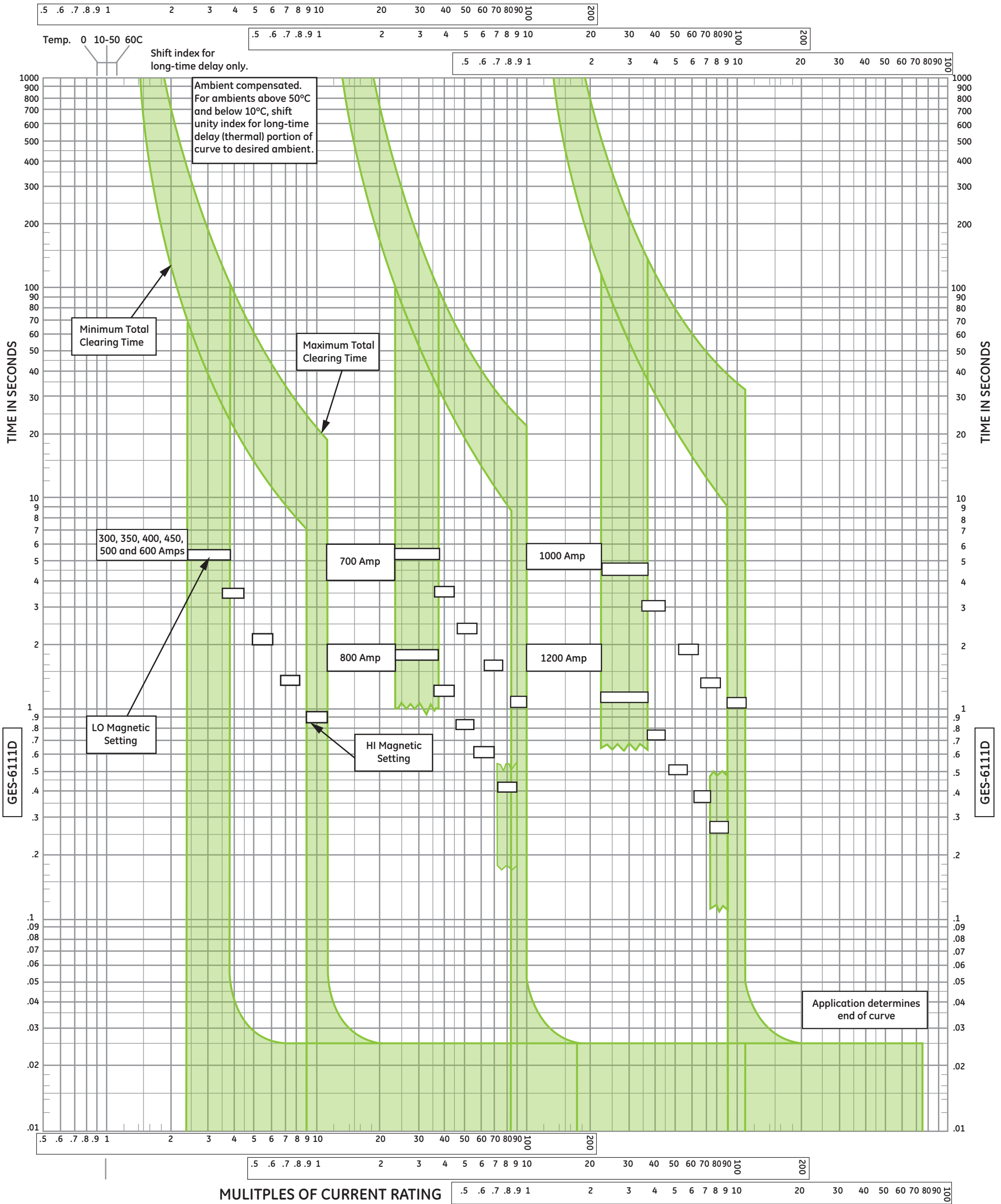

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

300, 350, 400, 450, 500, 600, 700, 800
1000 and 1200 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Ratings

Dc or 60 Hertz for 300-800 Amperes
60 Hertz for 1000-1200 Amperes

**Molded-Case Circuit Breaker
K 1200 Line**

Types TKMA & THKMA
(300-1200 Amperes)

**Long-Time Delay and Instantaneous
Time-Current Curves**

Curves show ambient-compensated circuit breaker in open air, 10-50°C, wired with conductors of corresponding rating, no prior load. For all other ambients, use rating shift index at top of sheet.

GES-6111D

Adjustments

Long-time delay thermal trip: not adjustable.
Instantaneous magnetic trip: continuously adjustable, factory set on HI.

Dc magnetic trip level approximately 40% higher than ac values.

Blocks show trip range at marked points on instantaneous dials.