


0-50°C

MULTIPLES OF CURRENT RATING

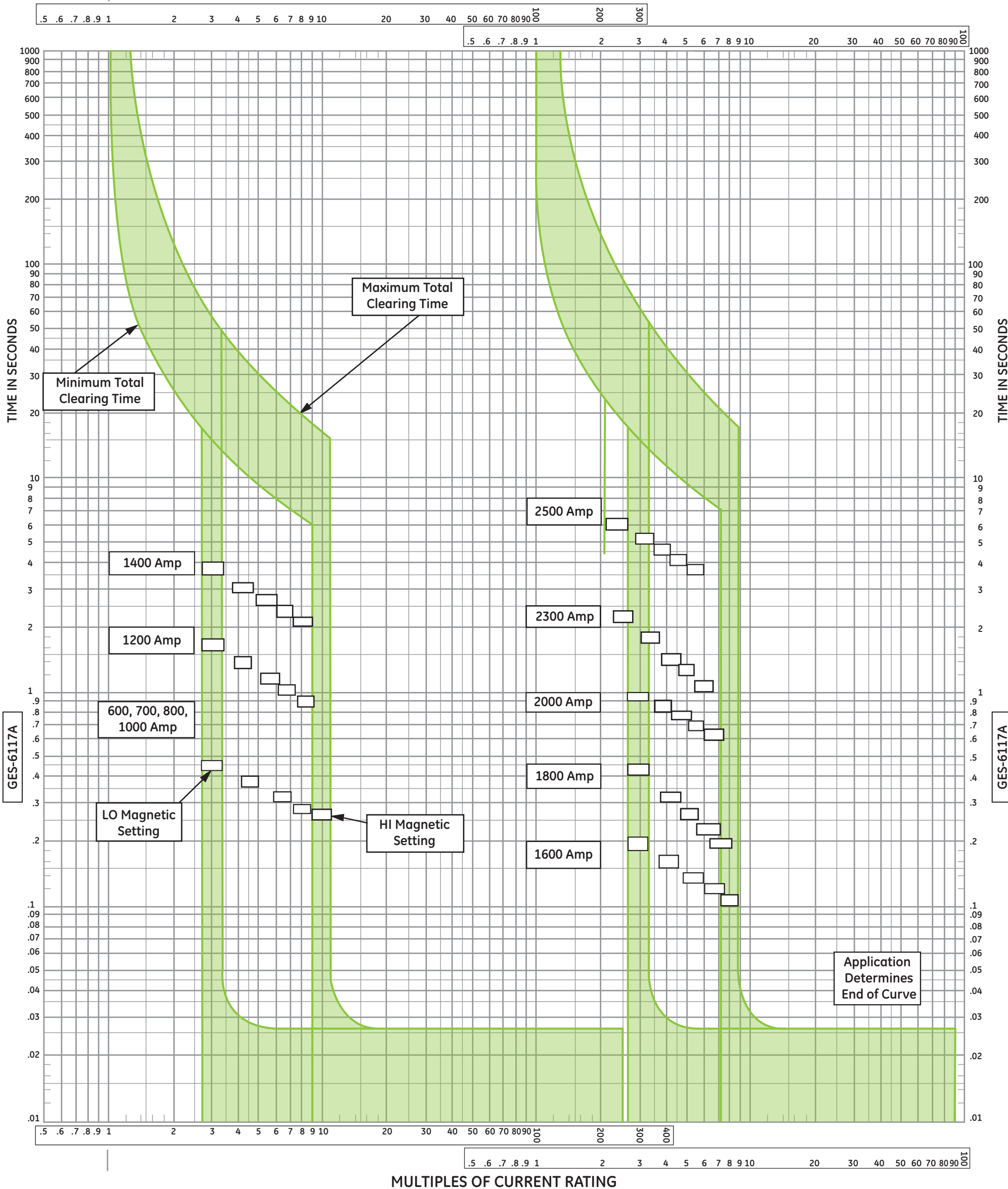

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300 and 2500 Amperes

Voltage Rating

600 Vac

Frequency Rating

60 Hertz

Molded Case Circuit Breaker S-2500 LINE

Long-time Delay and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.


GES-6117A

Adjustments

Long-time magnetic delay, not adjustable, or
long-time magnetic delay, adjustable.

Instantaneous magnetic trip, continuous adjustment,
factory set on HI.

Blocks show trip range at each setting.

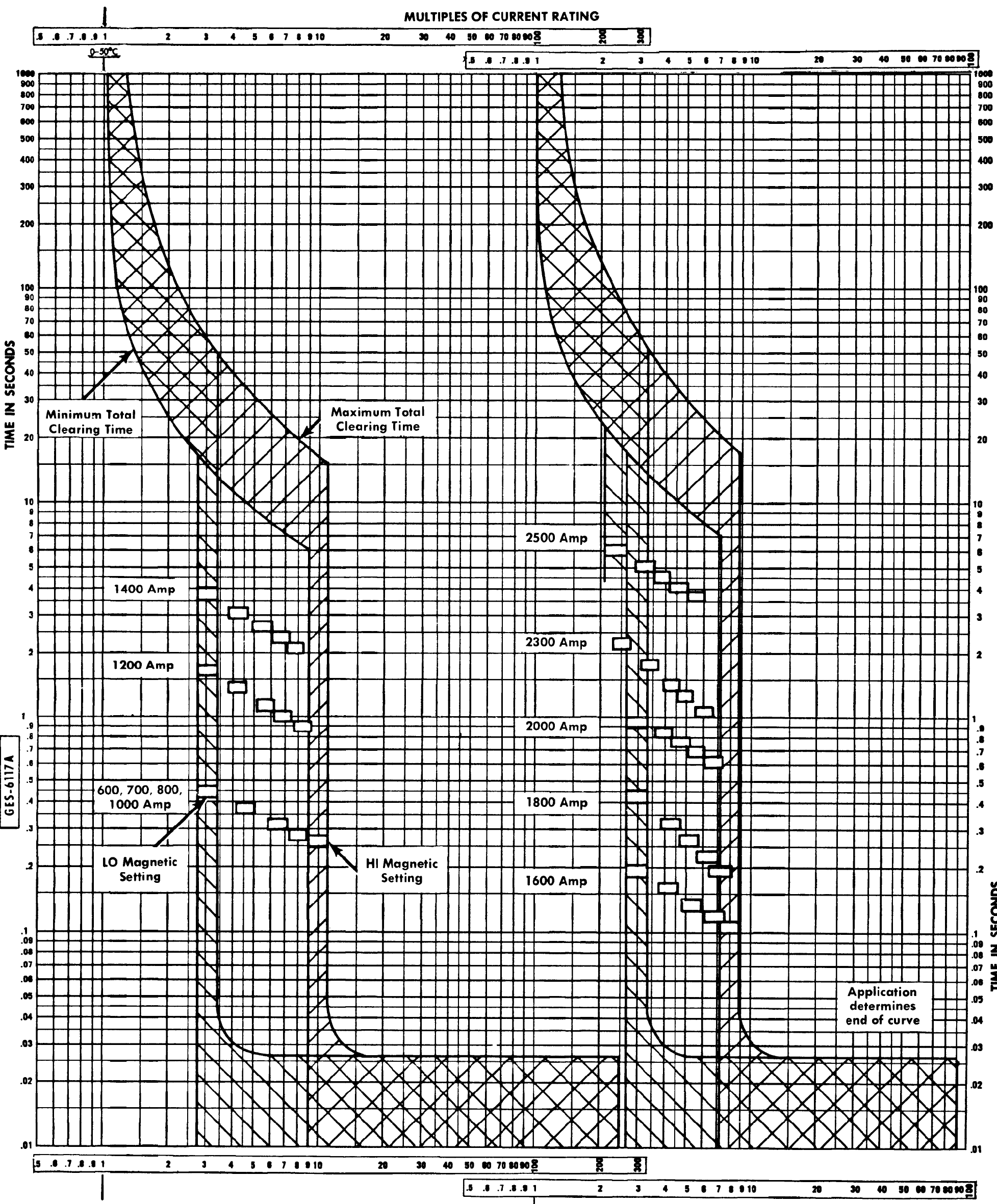

GENERAL ELECTRIC

Current Ratings
600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300, and 2500 amperes

Voltage Ratings
600 volts ac

Frequency Ratings
60 Hertz

MOLDED-CASE CIRCUIT BREAKER

S-2500 LINE

**Long-time Delay and Instantaneous
Time-current Curves**

GES-6117A
Replaces GES-1117

Adjustments

Long-time magnetic delay, not adjustable,
or long-time magnetic delay, adjustable.

Instantaneous magnetic trip, continuous ad-
justment, factory set on HI.

Blocks show trip range at each setting.

(Curves show circuit breaker in open air, 0-50 C ambient, wired with conductors of corresponding rating, no prior load.)