


MULTIPLES OF CURRENT RATING

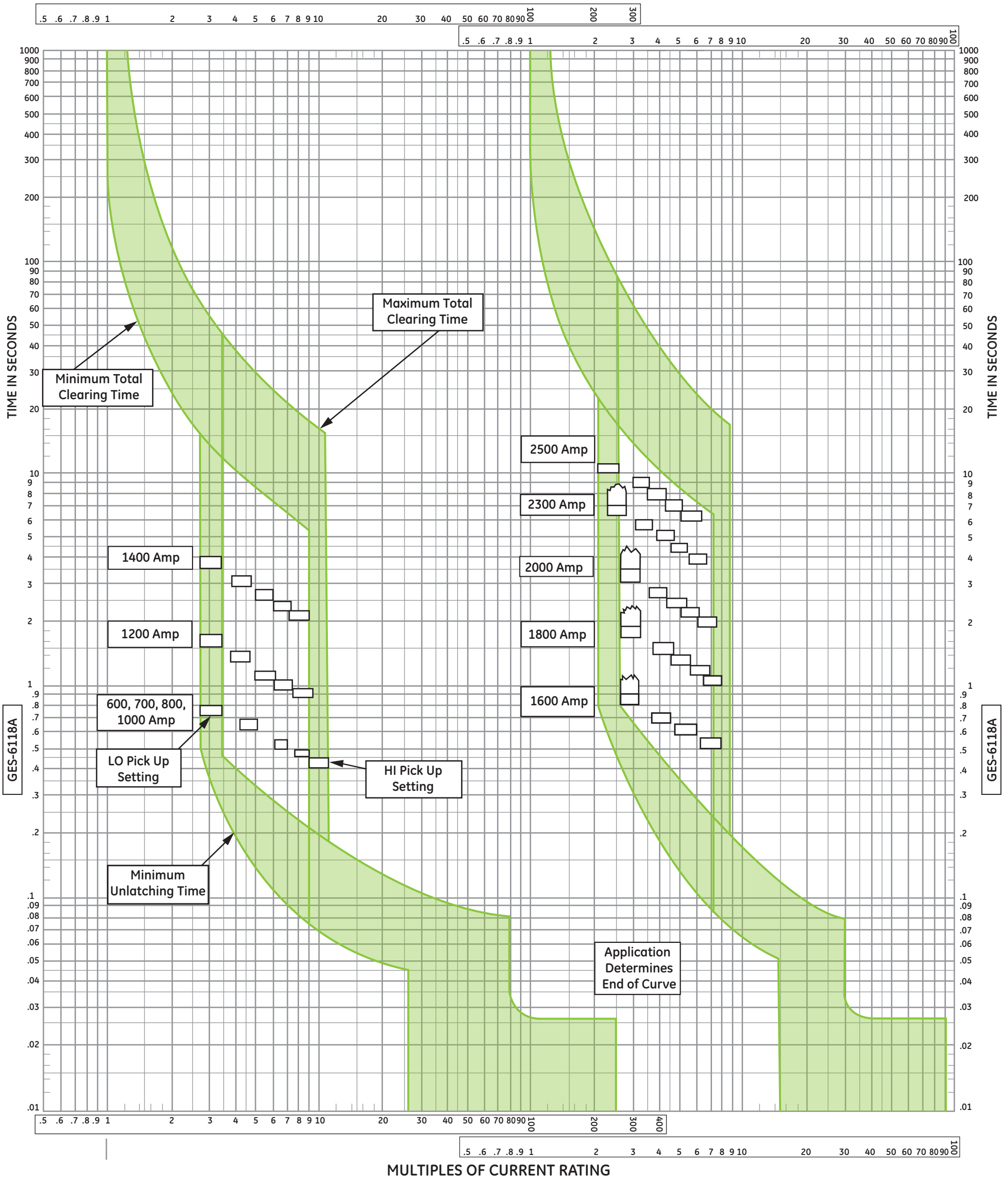

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

600, 700, 800, 1000, 1200, 1400, 1600,
1800, 2000, 2300 and 2500 Amperes

Voltage Ratings

600 Vac

Frequency Rating

60 Hertz

**Molded Case Circuit Breaker
S-2500 LINE**

Dual Selective Trip

**Long-time Delay, Short-time Delay
and Instantaneous Time-current Curves**

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6118A

Adjustments


Long-time magnetic delay, not adjustable, or long-time
magnetic delay adjustable for 70-100%.

Short-time magnetic delay, adjustable pick up as
indicated by blocks shown for each setting.

Instantaneous magnetic trip, fixed 42,000 sym
amperes irrespective of trip unit rating.

MULTIPLES OF CURRENT RATING

5 6 7 8 9 1 2 3 4 5 6 7 8 9 10 20 30 40 50 60 70 80 90 100 200 300

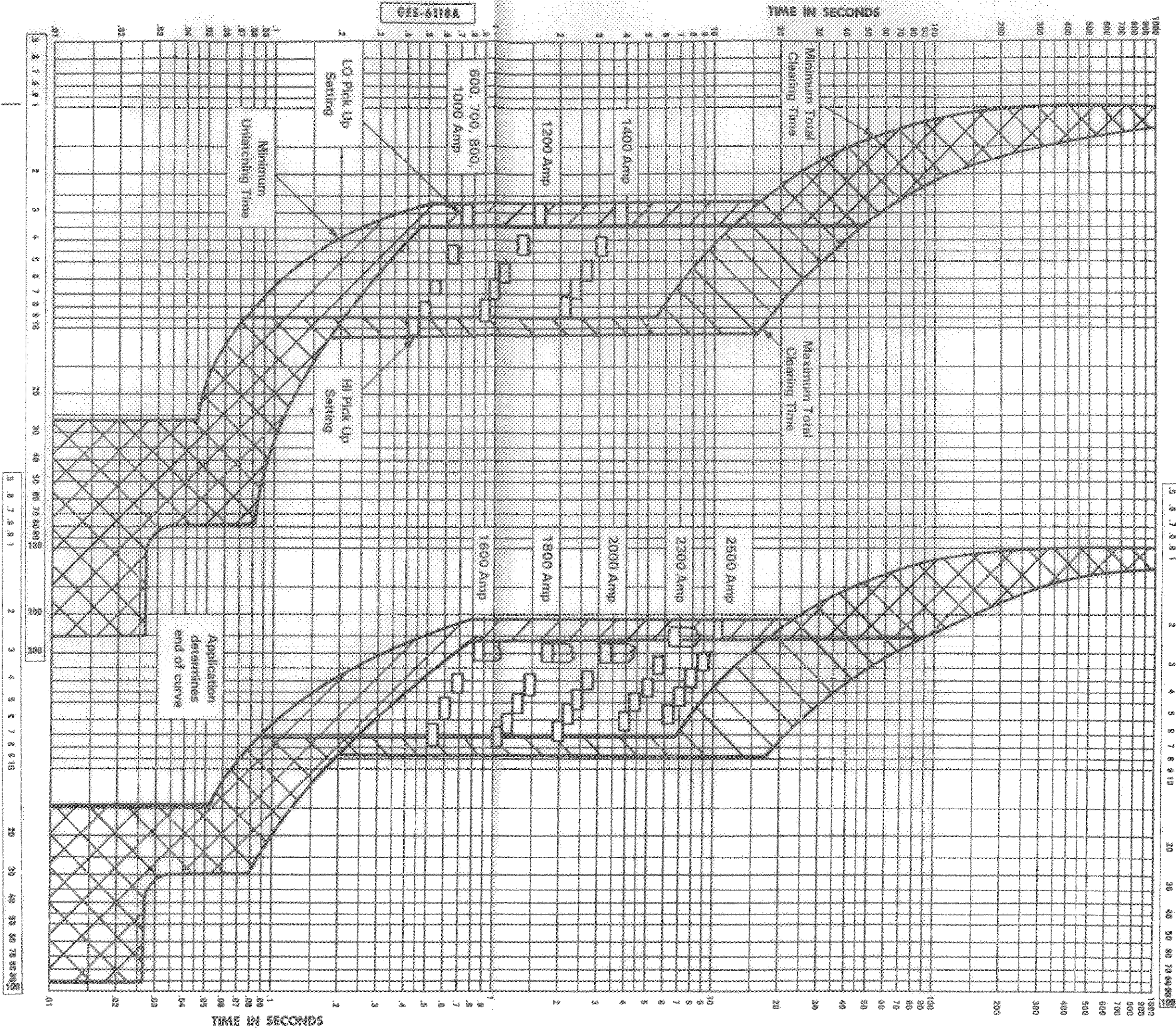

GES-6118A

GENERAL ELECTRIC

MOLDED-CASE CIRCUIT BREAKER
S-2500 LINE

GES-6118A
Replaces GES-6118

Current Ratings
600, 700, 800, 1000, 1200, 1400, 1600
1800, 2000, 2300, and 2500 amperes

Voltage Ratings
600 volts ac

Frequency Ratings
60 Hertz

Dual Selective Trip
Long-time Delay, Short-time Delay and Instantaneous Time-current Curves

Curves show circuit breaker in open air, 0-50C ambient, wired with conductors of corresponding rating, no prior load.

Adjustments
Long-time magnetic delay, not adjustable, or long-time magnetic delay adjustable for 70-100%.

Short-time magnetic delay, adjustable pick up as indicated by blocks shown for each setting.

Instantaneous magnetic trip, fixed 42,000 sym amperes irrespective of trip unit rating.

(1-81) (3M)

GENERAL ELECTRIC CO., DISTRIBUTION EQUIPMENT DIVISION, PLAINVILLE, CONN. 06062

K215-82C