


0-50°C

MULTIPLES OF CURRENT RATING

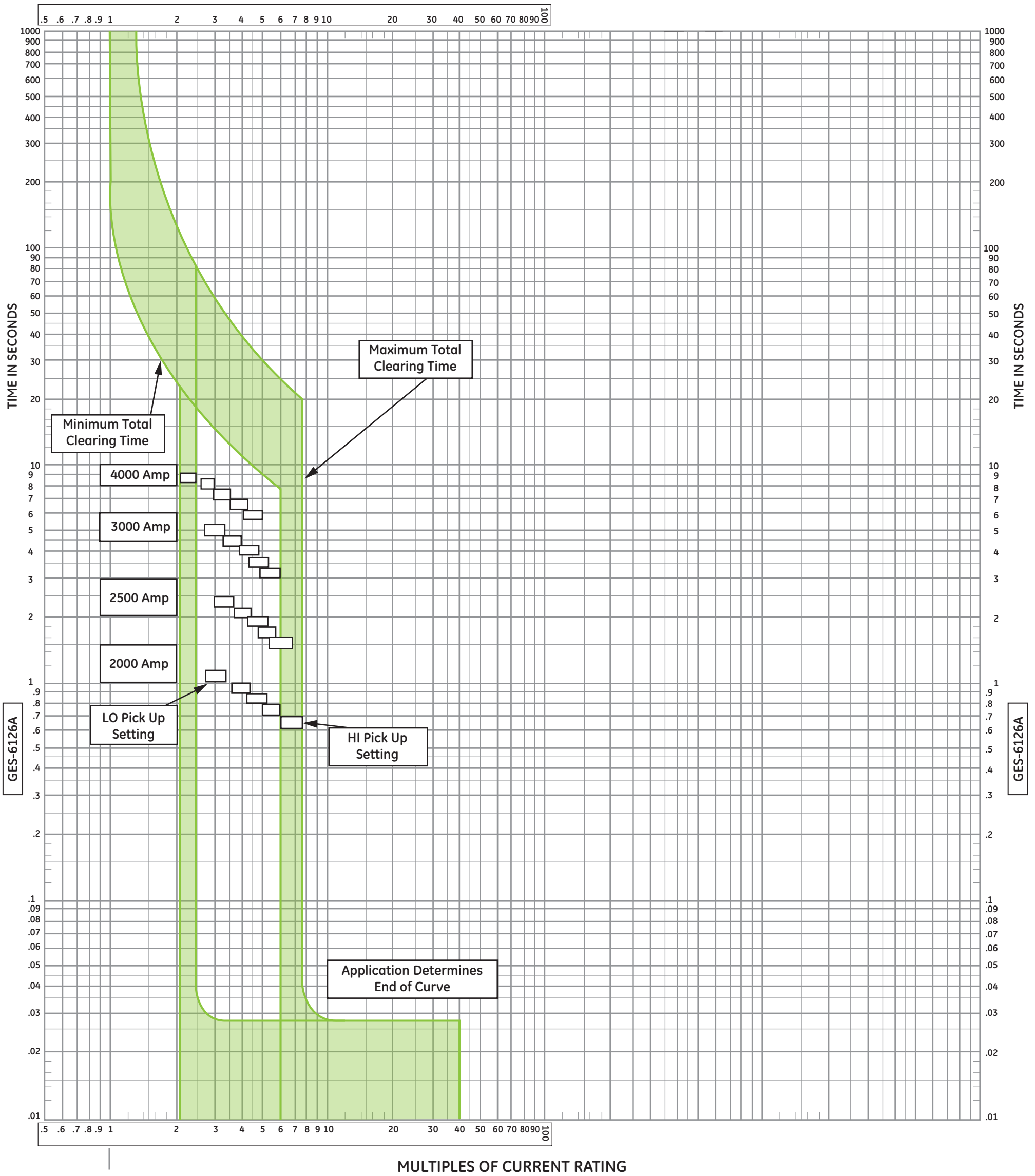

GE Consumer & Industrial -
Electrical Distribution

Current Ratings

3000A Frame — 2000, 2500 and 3000
Amperes

4000A Breaker — 4000 Amperes

Voltage Ratings

600 Vac, 250 Vdc

Frequency Rating

60 Hertz

Molded Case Circuit Breaker POWER BREAK™

Type TPS
(3000A Frame & 4000A Breaker)
Long-time Delay and Instantaneous
Time-current Curves

Curves show circuit breaker in open air, 0°C
to 50°C ambient, wired with conductors of
corresponding rating, no prior load.

GES-6126A


Adjustments

Long-time magnetic delay, not adjustable.


Instantaneous magnetic trip, continuous adjustment,
factory set on HI.

Blocks show trip range at each setting.

MULTIPLES OF CURRENT RATING

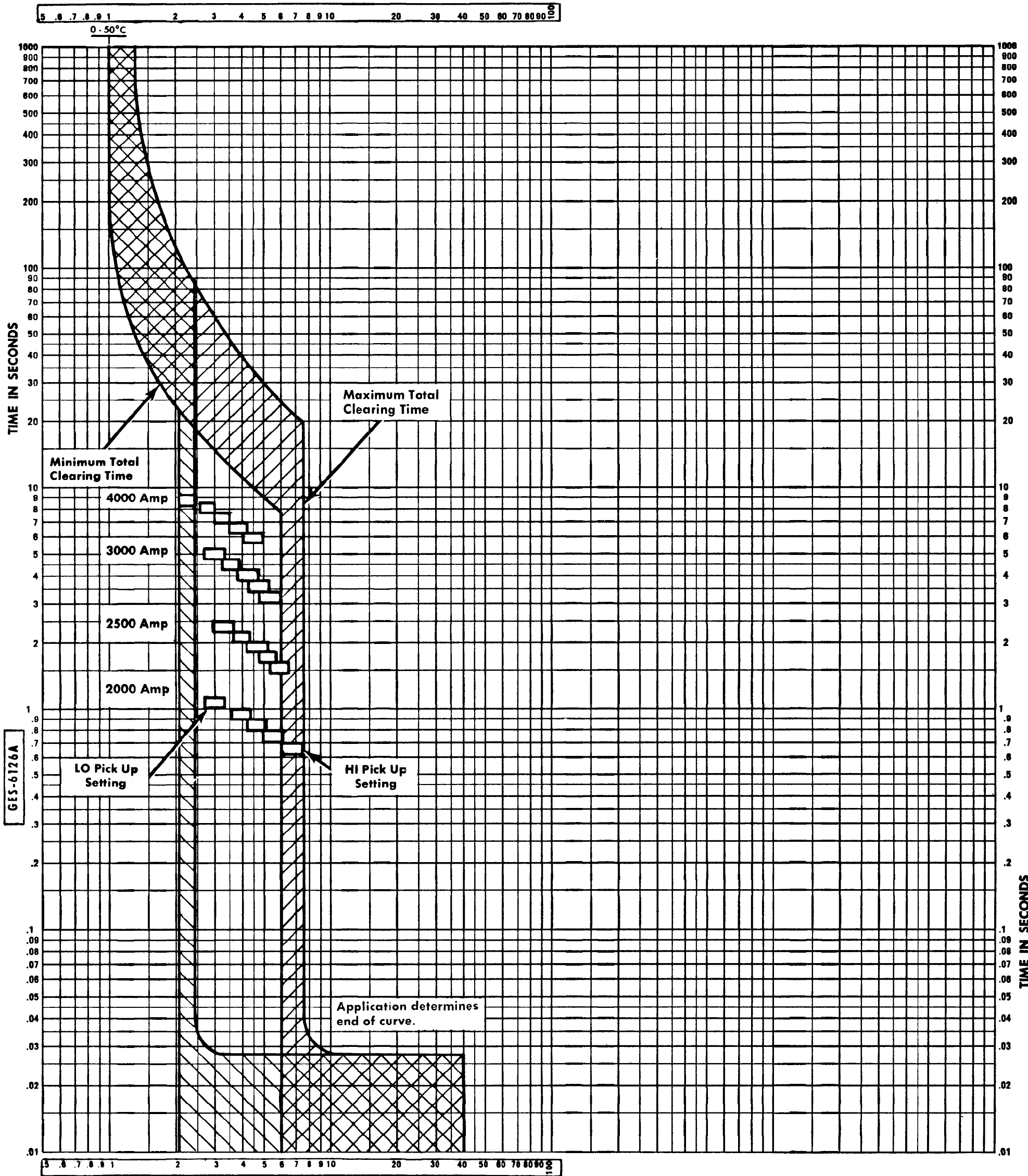

MULTIPLES OF CURRENT RATING

 <p>GENERAL ELECTRIC</p>	<p>MOLDED-CASE CIRCUIT BREAKER</p> <p>POWER BREAK™</p> <p>Type TPS (3000A Frame & 4000A Breaker)</p> <p>Long-time Delay and Instantaneous Time-Current Curves</p> <p>(Curves show circuit breaker in open air, 0-50 C ambient, wired with conductors of corresponding rating, no prior load.)</p>	<p>GES-6126A</p> <p>Adjustments</p> <p>Long-time magnetic delay, not adjustable.</p> <p>Instantaneous magnetic trip, continuous adjustment, factory set on HI.</p> <p>Blocks show trip range at each setting</p>
<p>Current Ratings: 3000A Frame — 2000, 2500 and 3000 amperes 4000A Breaker — 4000 amperes</p> <p>Voltage Ratings 600 volts ac, 250 volts dc</p> <p>Frequency Rating 60 Hertz</p>		